


# Assembly Parts for Rugged Components

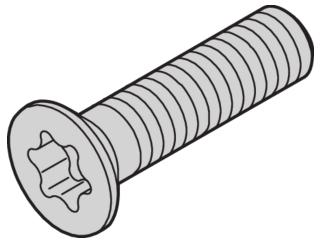

Assembly parts with thread-locking compound for rugged Side Panel, horizontal rail, cover plates, rear angle.

## CERTIFICATIONS



## FEATURES

Screws for the following fixings: Rugged side panel - horizontal rail, Rugged side panel - cover plate, Rugged side panel - rear angle

## SPECIFICATIONS

**Product Type:** Assembly Kit

**Product Family:** EuropacPRO

Table 1/2

Catalog Number	Type	Length	Package Quantity	Thread Size	Finish	Material
24566-105	Countersunk Screw	7mm	100	M4		Stainless Steel
24560-140	Square Nut		100		Zinc Plated	Steel
24566-106	Countersunk Screw	10mm	100	M4		Stainless Steel
24566-101	Countersunk Screw	14mm	100	M4		Stainless Steel

CatalogNumber	Type	Length	Package Quantity	Thread Size	Finish	Material
24566-100	Countersunk Screw	18mm	100	M4		Stainless Steel
24566-104	Panhead Screw	8mm	100	M4		Stainless Steel
24566-103	Panhead Screw	10mm	100	M4		Stainless Steel
24566-102	Panhead Screw	14mm	100	M4		Stainless Steel

Table 2/2

Catalog Number	Works With	Quick Ship
24566-105	Subracks	No
24560-140	Subracks	No
24566-106	Subracks	No
24566-101	Subracks	No
24566-100	Subracks	No
24566-104	Subracks	No
24566-103	Subracks	No
24566-102	Subracks	No

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**