


Plug-In Unit Microswitch for XL Handle With Cable and Plug

CATALOG NUMBER

20817-877

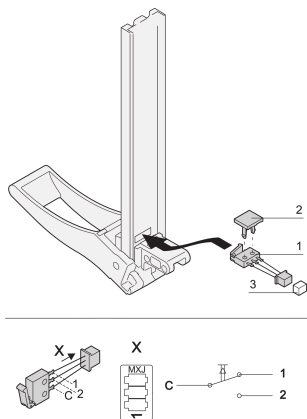

Micro Switch for XL Front panel.

CERTIFICATIONS



FEATURES

Electr. life $\geq 20,000$ switching cycles

Plastic, PC, UL 94 V-0

Molex connector housing

Suitable mating connectors not included in scope of delivery

Mech. life $\geq 20,000$ switching cycles

Operating range $-25\text{ }^{\circ}\text{C}$ to $+70\text{ }^{\circ}\text{C}$

Micro switch for XL handle

Max. switched current 50 mA

Molex crimp contact and fixing clip

PRODUCT ATTRIBUTES

Product Type: Switch
Works With: Front Panels
Package Quantity: 10
Depth: 35.59mm
Gross Weight: 0.012kg
Height: 8.2mm
Material: Polybutylene Terephthalate
Width: 7.84mm

ADDITIONAL PRODUCT DETAILS

Mating connector not included in delivery. Mating connectors from Molex e.g. 53261-0319, 53048-0310, 53047-0310, 53398-0319, 51047-0300.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE