


U-profile Front Panel, Shieldable, D-Sub Cutouts

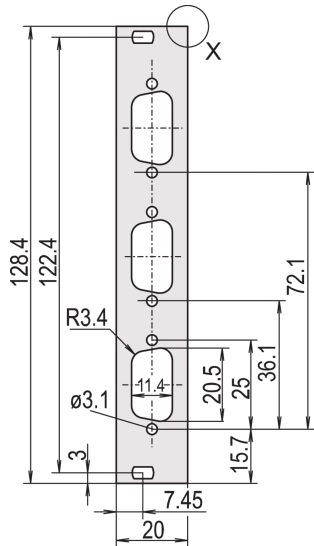

U-profile front panel with cutout for D-Sub connectors.
Shieldable for textile EMC gasket.

CERTIFICATIONS



FEATURES

U-profile, front panel, Al, 2.5 mm, front anodized, rear conductive

For EMC textile gasket

SPECIFICATIONS

Depth (D):	2.5mm
Rack Height:	3U
Rack Width:	4HP
Material:	Aluminum
Finish:	Anodized; Passivated
Accessory Type:	Front panel
Product Type:	Front Panel
Type:	Front Panel without Handle

EMC Shielding: No (Retrofittable)

Table 1/2

Catalog Number	Package Quantity	Mounting	Front Finish	Rear Finish	Number of Pins	Treated Edges
30849-751	1	Screw-on Front	Anodized	Conductive	(3) 9	No
30849-750	1	Screw-on Front	Anodized	Conductive	(2) 9	No
30849-752	1	Screw-on Front	Anodized	Conductive	(1) 15	No
30849-754	1	Screw-on Front	Anodized	Conductive	(1) 25	No
30849-753	1	Screw-on Front	Anodized	Conductive	(2) 15	No
30849-755	1	Screw-on Front	Anodized	Conductive	(2) 25	No
30849-749	1	Screw-on Front	Anodized	Conductive	(1) 9	No

Table 2/2

Catalog Number	Complies With	Height (H)	Width (W)	Quick Ship
30849-751	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	No
30849-750	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	No
30849-752	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	No
30849-754	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	No
30849-753	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	No
30849-755	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	No
30849-749	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	No

ADDITIONAL PRODUCT DETAILS


Please order fixing material (sleeves, collar screws) separately.


Delivery is in standard pack multiples. Pricing is per individual item.

Please order textile EMC gasket separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

DIAGRAMS

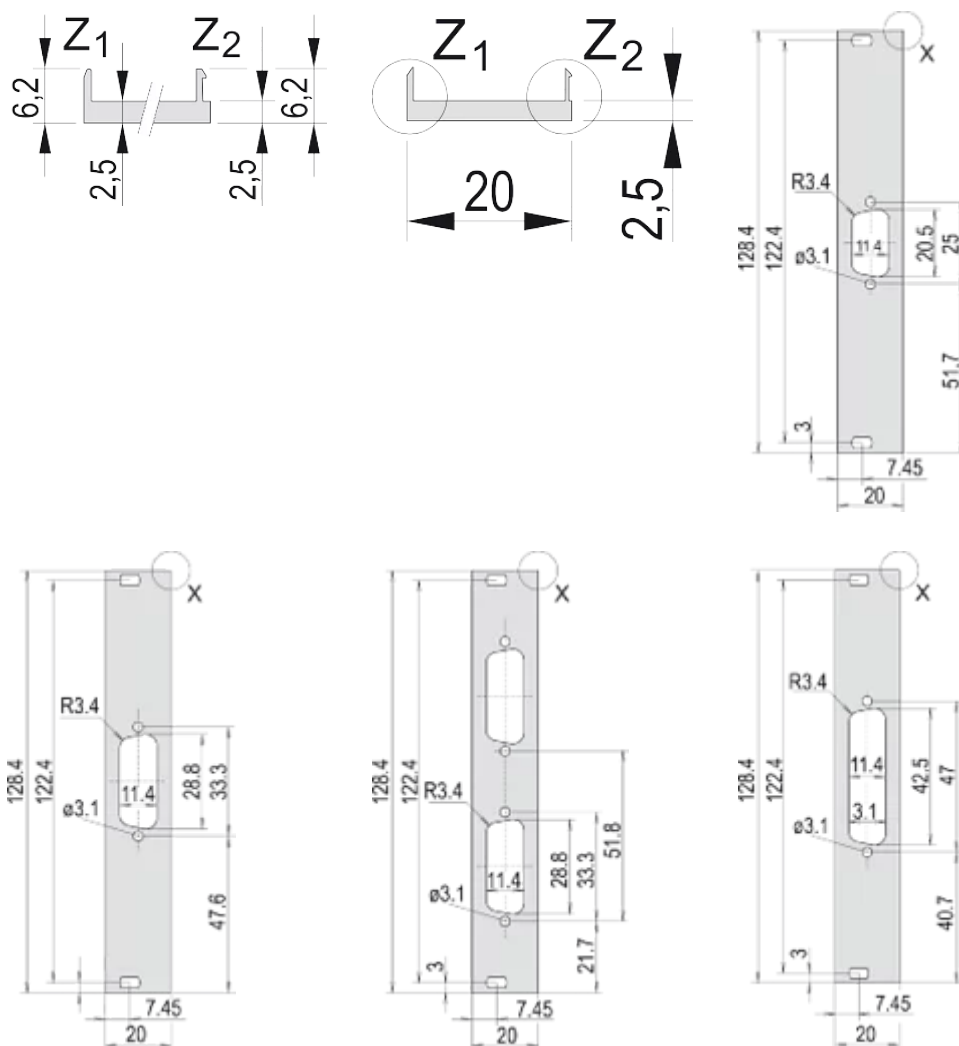

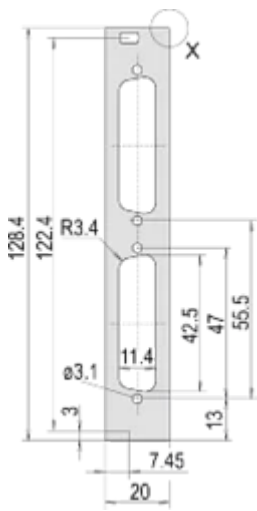

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE