

# nVent CADDY Macrofix Plus NI EZ with Easy Closure



## CERTIFICATIONS



## FEATURES

Contains easy closing mechanism

Plastic washers help prevent crushing the CPVC or plastic pipe and assure a floating fit

Flared edges and specially designed welding area help protect CPVC piping

Ideal for installations where space is limited and require services to be ran close to the attachment surface

Suitable for 3/4" - 2" (20 - 50 DN) steel sprinkler pipe

Eliminates the need to seismically brace when drops are kept within 6" (150 mm) of the attachment surface

Combo head bolt works with slotted, hex, or Phillips drivers

Conforms with Manufacturers Standardization Society (MSS) SP-58 (Type 12)

## SPECIFICATIONS

**Finish:** Electrogalvanized

**Material:** Steel

Table 1/2


| Catalog Number | Article Number | NB/DN | Outer Diameter (OD) | Rod Size (RS) | Width (W) | Thickness (T) |
|----------------|----------------|-------|---------------------|---------------|-----------|---------------|
| MPZ020         | 595052         | 15    | 20.0 - 21.3 mm      | M10           | 30 mm     | 1.5 mm        |
| MPZ025         | 595053         | 20    | 25.0 - 26.9 mm      | M10           | 30 mm     | 1.5 mm        |
| MPZ032         | 595054         | 25    | 32.0 - 33.7 mm      | M10           | 30 mm     | 1.5 mm        |
| MPZ040         | 595056         | 32    | 40.0 - 42.4 mm      | M10           | 30 mm     | 1.5 mm        |
| MPZ050         | 595057         | 40    | 48.3 - 50 mm        | M10           | 30 mm     | 2 mm          |
| MPZ063         | 595059         | 50    | 60.3 - 63 mm        | M10           | 30 mm     | 2 mm          |
| MPZ075         | 595061         | 65    | 75.0 - 76.1 mm      | M10           | 30 mm     | 2 mm          |
| MPZ110         | 595063         | 100   | 110.0 - 114.3 mm    | M10           | 30 mm     | 2.5 mm        |

Table 2/2

| Catalog Number | Article Number | Static Load | Certifications                                                                |
|----------------|----------------|-------------|-------------------------------------------------------------------------------|
| MPZ020         | 595052         | 1125N       | AON Fire Protection, BB019, pipe hangers                                      |
| MPZ025         | 595053         | 1125N       | AON Fire Protection, BB019, pipe hangers, FM Approved, Pipe Hanger Components |
| MPZ032         | 595054         | 1125N       | FM Approved, Pipe Hanger Components, AON Fire Protection, BB019, pipe hangers |
| MPZ040         | 595056         | 1125N       | AON Fire Protection, BB019, pipe hangers, FM Approved, Pipe Hanger Components |
| MPZ050         | 595057         | 1725N       | FM Approved, Pipe Hanger Components, AON Fire Protection, Macrofix Plus NI EZ |
| MPZ063         | 595059         | 1725N       | AON Fire Protection, Macrofix Plus NI EZ, FM Approved, Pipe Hanger Components |

| Catalog Number | Article Number | Static Load | Certifications |
|----------------|----------------|-------------|----------------|
| MPZ075         | 595061         | 1725N       |                |
| MPZ110         | 595063         | 2000N       |                |

### DIAGRAMS

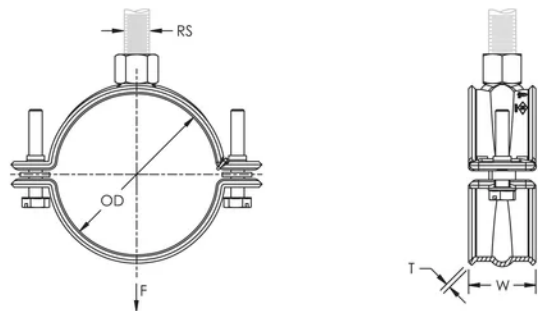

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221  
 Option 1 – Customer Care  
 Option 2 – Technical Support

#### Europe

Netherlands:  
 +31 800-0200135  
 France:  
 +33 800 901 793

#### Europe

Germany:  
 800 1890272  
 Other Countries:  
 +31 13 5835404

#### APAC

Shanghai:  
 + 86 21 2412 1618/19  
 Sydney:  
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE

