


PESMTS, Medium Duty Pipe Slide with Strap, Two Connectors

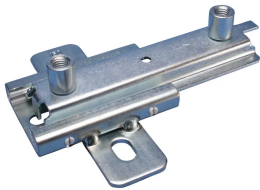

FEATURES

For use with two pipe clamps


Includes welded on mounting strap

SPECIFICATIONS

Catalog Number	PESMTS
Article Number	580563
Material	Steel Polyamide
Finish	Electrogalvanized
Rod Size (RS)	M10 M12
Height (H)	46 mm
Length (L)	165mm
Δ Length (ΔL)	140 mm
Width (W)	150 mm
A	100 mm
B	40 mm
C	123 mm
X	12.5 x 20 mm

Catalog Number	PESMTS
Temperature	120 °C Max
Static Load 1 (F1)	2300N
Static Load 2 (F2)	2300N

DIAGRAMS

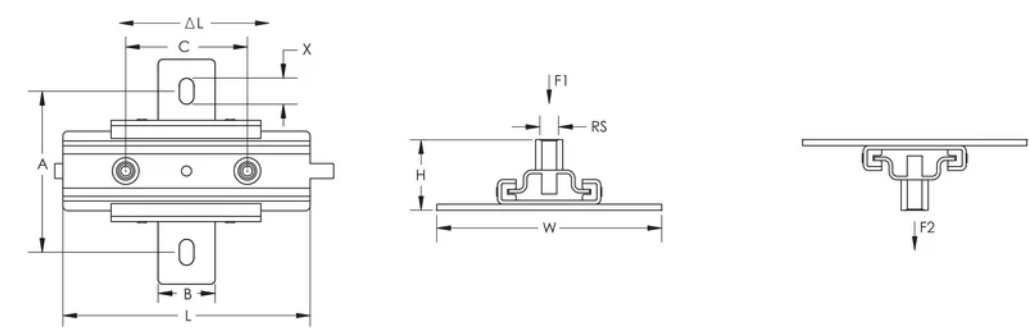

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

