


U-profile Front Panel, Shieldable, D-Sub Cutouts

Power Utilities

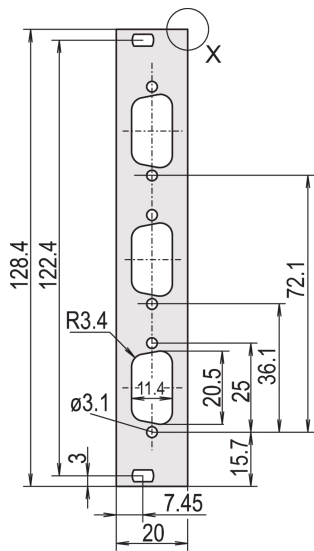

U-profile front panel with cutout for D-Sub connectors.
Shieldable for textile EMC gasket.

CERTIFICATIONS



FEATURES

U-profile, front panel, Aluminum, 2.5 mm, front anodized, rear conductive

For EMC textile gasket

SPECIFICATIONS

Table 1/3

Catalog Number	Package Quantity	Mounting	Front Finish	Rear Finish	Treated Edges	Complies With
30849-749	5	Screw-on Front	Anodized	Conductive	No	IEC 60297-3-101, IEEE 1101.1/10

CatalogNumber	Package Quantity	Mounting	Front Finish	Rear Finish	Treated Edges	Complies With
30849-750	5	Screw-on Front	Anodized	Conductive	No	IEC 60297-3-101, IEEE 1101.1/10
30849-751	5	Screw-on Front	Anodized	Conductive	No	IEC 60297-3-101, IEEE 1101.1/10
30849-752	5	Screw-on Front	Anodized	Conductive	No	IEC 60297-3-101, IEEE 1101.1/10
30849-753	5	Screw-on Front	Anodized	Conductive	No	IEC 60297-3-101, IEEE 1101.1/10
30849-754	5	Screw-on Front	Anodized	Conductive	No	IEC 60297-3-101, IEEE 1101.1/10
30849-755	5	Screw-on Front	Anodized	Conductive	No	IEC 60297-3-101, IEEE 1101.1/10

Table 2/3

Catalog Number	EMC Shielding	Height	Material	Product Type	Rack Height	Rack Width
30849-749	No (Retrofittable)	128.4 mm	Aluminum	Front Panel	3 U	4 HP
30849-750	No (Retrofittable)	128.4 mm	Aluminum	Front Panel	3 U	4 HP
30849-751	No (Retrofittable)	128.4 mm	Aluminum	Front Panel	3 U	4 HP
30849-752	No (Retrofittable)	128.4 mm	Aluminum	Front Panel	3 U	4 HP
30849-753	No (Retrofittable)	128.4 mm	Aluminum	Front Panel	3 U	4 HP
30849-754	No (Retrofittable)	128.4 mm	Aluminum	Front Panel	3 U	4 HP
30849-755	No (Retrofittable)	128.4 mm	Aluminum	Front Panel	3 U	4 HP

Table 3/3

Catalog Number	Type	Width
30849-749	Front Panel without Handle	20 mm

Catalog Number	Type	Width
30849-750	Front Panel without Handle	20 mm
30849-751	Front Panel without Handle	20 mm
30849-752	Front Panel without Handle	20 mm
30849-753	Front Panel without Handle	20 mm
30849-754	Front Panel without Handle	20 mm
30849-755	Front Panel without Handle	20 mm

ADDITIONAL PRODUCT DETAILS

Please order fixing material (sleeves, collar screws) separately.

Delivery is in standard pack multiples. Pricing is per individual item.

Please order textile EMC gasket separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE