


# Combined Mounting Kit for Chassis

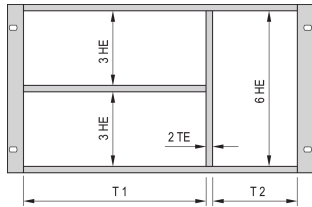

The combined mounting enable the option to split a 6 U high subrack or case in 2 x 3 U and 6 U sections. Different versions are available.

## CERTIFICATIONS



## FEATURES

Designed to accept Euroboards (100 mm high) and double Euroboards (233.35 mm high)

Subdivision of the 6 U assembly area into: 2 x 3 U, 1 x 6 U

## SPECIFICATIONS

|                        |              |
|------------------------|--------------|
| <b>Rack Height:</b>    | 6U           |
| <b>Type:</b>           | Combined     |
| <b>Product Family:</b> | EuropacPRO   |
| <b>Product Type:</b>   | Mounting Kit |
| <b>Works With:</b>     | Subracks     |

Table 1/1

| Catalog Number | Package Quantity | Rack Width 1 | Rack Width 2 | Material             | Quick Ship |
|----------------|------------------|--------------|--------------|----------------------|------------|
| 24562-420      | 1                | 20HP         | 62HP         | Aluminum, Zinc Alloy | No         |
| 24562-440      | 1                | 40HP         | 42HP         | Aluminum, Zinc Alloy | No         |
| 24562-442      | 1                | 42HP         | 40HP         | Aluminum, Zinc Alloy | No         |

| Catalog Number | Package Quantity | Rack Width 1 | Rack Width 2 | Material             | Quick Ship |
|----------------|------------------|--------------|--------------|----------------------|------------|
| 24562-484      | 1                | 84HP         |              | Aluminum, Zinc Alloy | No         |
| 24562-463      | 1                | 63HP         | 19HP         | Aluminum, Zinc Alloy | No         |

## ADDITIONAL PRODUCT DETAILS

Please order separately: Front panel 6 U, 2 HP to cover the strut.

The following guide rails cannot be used: type "accessory", type "accessory, strengthened" and type "for 4.4" PCB".

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**