


# Grounding/Grounding Busbar Kit With Screw Clamps

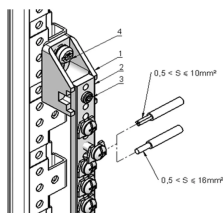

Metallic strip typically housed inside switchgear, panel boards, and busway enclosures for local high current power distribution. They are also used to connect high voltage equipment at electrical switchyards, and low voltage equipment in battery banks.

## FEATURES

To screw grounding cables with endpiece or stripped

Threaded fixing points M5 in intervals of 15 mm

Assembly insulated from the frame

Maximum current capacity 200 A

## SPECIFICATIONS

**Product Type:** Grounding Kit

Table 1/1

| Catalog Number | Length | Material | Package Quantity | Type        | Quick Ship |
|----------------|--------|----------|------------------|-------------|------------|
| 20118-859      | 200mm  | Copper   | 1                | Screw Clamp | No         |
| 20118-869      | 2000mm | Copper   | 1                | Screw Clamp | No         |
| 20118-868      | 1900mm | Copper   | 1                | Screw Clamp | No         |
| 20118-865      | 450mm  | Copper   | 1                | Screw Clamp | No         |
| 20118-867      | 1680mm | Copper   | 1                | Screw Clamp | No         |

| Catalog Number | Length | Material | Package Quantity | Type        | Quick Ship |
|----------------|--------|----------|------------------|-------------|------------|
| 20118-866      | 975mm  | Copper   | 1                | Screw Clamp | No         |

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**