


Rivet Head Shear Bolt

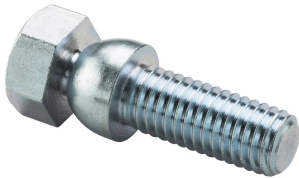

FEATURES

One wrench size fits all required hardware, eliminating the need to change tools

SPECIFICATIONS


Table 1/2

Catalog Number	Article Number	Material	Finish	Product	Width (W)	Screw Length (L)
CSBSBR50EG	404578	Steel	Electrogalvanized	Strut Seismic Hinge Bracket Assembly, Trapeze Sway Brace, Strut, Universal Structural Bracket, Strut Brace	19 mm	31.8mm

Table 2/2

Catalog Number	Article Number	A
CSBSBR50EG	404578	13.2 mm

 DIAGRAMS



WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

