

Multi-Purpose Grounding Clamp



FEATURES

Cross connector for round-to-round, round-to-tape, and tape-to-tape connections

SPECIFICATIONS


Table 1/2

Catalog Number	Article Number	Material	Finish	Conductor Size	Tape Size	Depth (D)
CCG308	545180	Steel	Hot-Dip Galvanized	8 mm Stranded, 8 mm Solid	25 x 3 mm, 30 x 3.5 mm	56mm
CCS-308	545170	Stainless Steel 304 (EN 1.4301)		8 mm Stranded, 8 mm Solid	25 x 3 mm, 30 x 2 mm	56mm

Table 2/2

Catalog Number	Article Number	Width (W)	Unit Weight
CCG308	545180	56 mm	0.15 kg
CCS-308	545170	56 mm	0.15 kg

DIAGRAMS

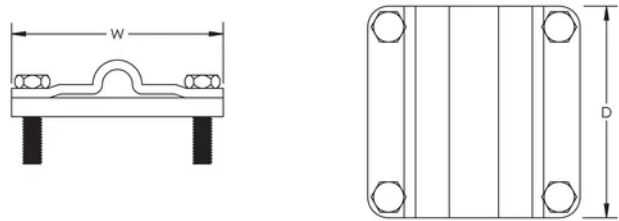

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE