


# QCC nVent ERIFLEX Flexibar Clamp, 40–63 mm

## CATALOG NUMBER

**QCC40-63**

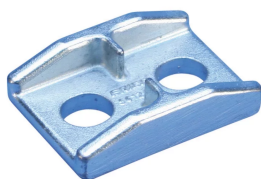

## CERTIFICATIONS



## FEATURES

Connects nVent ERIFLEX Flexibar to punched busbar

Allows for excellent electrical contact

Compact, space saving design

Installs quickly and easily

Ideal for on site modifications

## PRODUCT ATTRIBUTES

Article Number: 561220

Material: Steel

Finish: Electrogalvanized

Conductor Width: 40 - 63 mm

Depth (D): 13mm

Height (H): 35 mm

Width (W): 95 mm

Thickness (T): 5 mm

A: 75 mm

B: 10.5 mm


C: 11 mm

Unit Weight: 0.16 kg

## ADDITIONAL PRODUCT DETAILS

Use one clamp when nVent ERIFLEX Flexibar thickness is less than 5 mm (0.2") and two clamps when nVent ERIFLEX Flexibar thickness is greater than 5 mm (0.2").

## DIAGRAMS

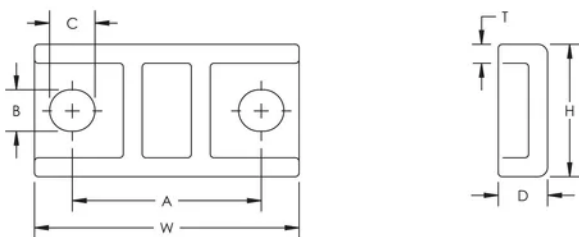

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**