


# FS66S 19-inch Rack Angle

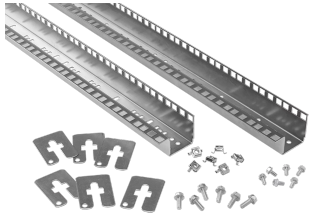

Rack angles accommodate 19-inch equipment. Furnished in pairs.

## FEATURES

---

All necessary mounting hardware is included.

SPECIFICATIONS

| Table 1/1      |            |             |           |                       |            |
|----------------|------------|-------------|-----------|-----------------------|------------|
| Catalog Number | Material   | Finish      | Thickness | Fits Enclosure Height | Quick Ship |
| FMPM1800G000S  | Mild Steel | Zinc Plated | 2mm       | 1800mm                | No         |
| FMPM2100G000S  | Mild Steel | Zinc Plated | 2mm       | 2100mm                | No         |
| FMPM2300G000S  | Mild Steel | Zinc Plated | 2mm       | 2300mm                | No         |
| FMPM2200G000S  | Mild Steel | Zinc Plated | 2.5mm     | 2200mm                | No         |
| FMPM2000G000S  | Mild Steel | Zinc Plated | 2.5mm     | 2000mm                | No         |
| FMPM1500G000S  | Mild Steel | Zinc Plated | 2.5mm     | 1500mm                | No         |

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE