 


# Disconnecting Link with Enclosure for Cable



## FEATURES

Allows for quick and easy disconnection of the earthing system to facilitate testing of the earth in isolation

High conductivity, hard drawn, electrolytic tough pitch copper per EN 13601

Includes stainless steel 304 enclosure, rubber dustproof, halogen-free polyamide insulators, stainless steel hardware

Compression straight lug: according to DIN46235 standard

Rubber gland for cable connection

8 microns tinned finish according to ASTM B545 Service Class "C"

## SPECIFICATIONS

Table 1/3

| Catalog Number | Material                                       | Finish | A     | Diameter (Ø) | Height (H) | Thickness (T) |
|----------------|------------------------------------------------|--------|-------|--------------|------------|---------------|
| DLCBX95        | Stainless Steel 304 (EN 1.4301), Copper        | Bare   | 90 mm | 20 mm        | 66.5 mm    | 4 mm          |
| DLTBX95        | Stainless Steel 304 (EN 1.4301), Tinned Copper | Tinned | 90 mm | 20 mm        | 66.5 mm    | 4 mm          |

Table 2/3

| Catalog Number | Thread Size (TS) | Length 1 (L1) | Length 2 (L2) | Length 3 (L3) | Length 4 (L4) | Width 1 (W1) |
|----------------|------------------|---------------|---------------|---------------|---------------|--------------|
| DLCBX95        | M8               | 125 mm        | 230 mm        | 210mm         | 160 mm        | 40 mm        |


| CatalogNumber | Thread Size (TS) | Length 1 (L1) | Length 2 (L2) | Length 3 (L3) | Length 4 (L4) | Width 1 (W1) |
|---------------|------------------|---------------|---------------|---------------|---------------|--------------|
| DLTBX95       | M8               | 125 mm        | 230 mm        | 210mm         | 160 mm        | 40 mm        |

| Table 3/3      |              |              |             |
|----------------|--------------|--------------|-------------|
| Catalog Number | Width 2 (W2) | Width 3 (W3) | Unit Weight |
| DLCBX95        | 150 mm       | 170mm        | 1.45 kg     |
| DLTBX95        | 150 mm       | 170mm        | 1.45 kg     |

### ADDITIONAL PRODUCT DETAILS

Available cable size ≤ 95 mm².

### DIAGRAMS

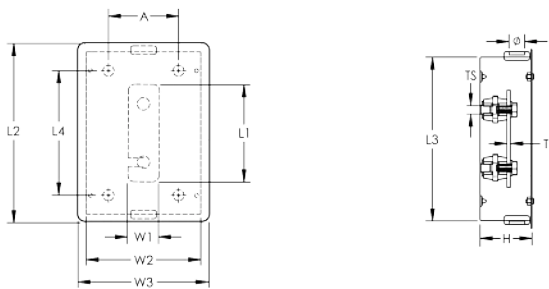

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**