


# Rail Stub End Bond, Power, C Style

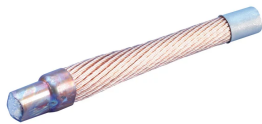

## FEATURES

- Provides unchanging electrical resistance
- Superior corrosion resistance
- Easy installation, with minimum installer training required
- Simple and highly-portable installation equipment
- Equally usable on old, worn, or new rails
- Highly durable
- Includes ropelay copper cable for maximum flexibility

## SPECIFICATIONS

Table 1/1

| Catalog Number | Material                    | Finish                      | Bond Terminal Style | Conductor Size    | Length (L) | Diameter (Ø) |
|----------------|-----------------------------|-----------------------------|---------------------|-------------------|------------|--------------|
| PBC32W9WSB     | Copper, Copper Alloy, Steel | Bare, Copper Plated, Tinned | C                   | 250 kcmil Ropelay | 228.6mm    | 14.6 mm      |

## DIAGRAMS



**WARNING**

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

**Europe**

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

**Europe**

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

**APAC**

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**