 


Steel Ground Plate



CERTIFICATIONS



FEATURES

Provides a large surface area to dissipate current into the ground

Includes a welded steel rod pigtail

SPECIFICATIONS

Material: Steel


Table 1/2

Catalog Number	Finish	Connector	Length 1 (L1)	Length 2 (L2)	Width (W)	Thickness (T)
EGGP	Electrogalvanized	None	406 mm	51 mm	254 mm	6.35 mm
EBGP	Plain	None	406 mm	51 mm	254 mm	6.35 mm
EGGPC	Electrogalvanized	HDC58	406 mm	51 mm	254 mm	6.35 mm

Table 2/2

Catalog Number	Diameter (Ø)	Certifications
EGGP	15.9 mm	UL, cUL
EBGP	15.9 mm	
EGGPC	15.9 mm	cUL, UL

DIAGRAMS

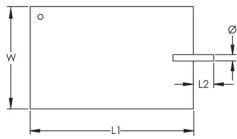

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical
 Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE