


Novastar Side Panel for Heavy-Duty

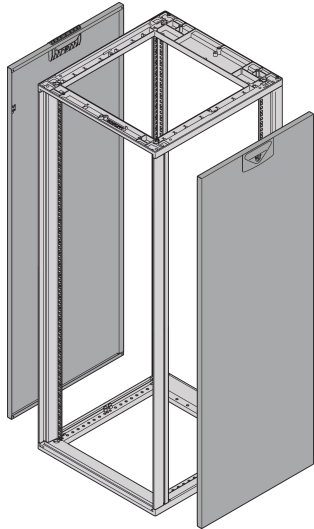

Steel Side Panels for Heavy-Duty aluminum frame with quick fastener for easy mounting and installation. Schroff delivers cladding parts with grounding cable installed and tested.

CERTIFICATIONS



FEATURES

With quick-release fastener, includes grounding

St. 1mm

SPECIFICATIONS

Product Type: Cabinet/Rack Panel

Material: Steel

Table 1/2

Catalog Number	Rack Height	Height	Depth	Package Quantity	Color	Color Code
25230-166	29U	1345mm	600mm	2	Black Grey	RAL 7021

CatalogNumber	Rack Height	Height	Depth	Package Quantity	Color	Color Code
25230-167	29U	1345mm	800mm	2	Black Grey	RAL 7021
25230-168	29U	1345mm	900mm	2	Black Grey	RAL 7021
25230-169	29U	1345mm	1000mm	2	Black Grey	RAL 7021
26230-165	29U	1345mm	500mm	2	Light Grey	RAL 7035
26230-166	29U	1345mm	600mm	2	Light Grey	RAL 7035
26230-167	29U	1345mm	800mm	2	Light Grey	RAL 7035
26230-168	29U	1345mm	900mm	2	Light Grey	RAL 7035
26230-169	29U	1345mm	1000mm	2	Light Grey	RAL 7035
25230-040	47U	2087mm	900mm	2	Black Grey	RAL 7021
25230-041	47U	2087mm	1000mm	2	Black Grey	RAL 7021
25230-067	12U	531mm	900mm	2	Black Grey	RAL 7021
25230-068	12U	531mm	1000mm	2	Black Grey	RAL 7021
25230-069	16U	709mm	900mm	2	Black Grey	RAL 7021
25230-080	16U	709mm	1000mm	2	Black Grey	RAL 7021
25230-103	20U	887mm	900mm	2	Black Grey	RAL 7021
25230-104	20U	887mm	1000mm	2	Black Grey	RAL 7021
25230-105	25U	1109mm	900mm	2	Black Grey	RAL 7021
25230-106	25U	1109mm	1000mm	2	Black Grey	RAL 7021

CatalogNumber	Rack Height	Height	Depth	Package Quantity	Color	Color Code
25230-107	34U	1509mm	900mm	2	Black Grey	RAL 7021
25230-108	34U	1509mm	1000mm	2	Black Grey	RAL 7021
25230-109	38U	1687mm	900mm	2	Black Grey	RAL 7021
25230-110	38U	1687mm	1000mm	2	Black Grey	RAL 7021
25230-111	43U	1909mm	900mm	2	Black Grey	RAL 7021
25230-112	43U	1909mm	1000mm	2	Black Grey	RAL 7021
25230-222	12U	531mm	500mm	2	Black Grey	RAL 7021
25230-223	16U	709mm	500mm	2	Black Grey	RAL 7021
25230-224	20U	945mm	500mm	2	Black Grey	RAL 7021
25230-225	25U	1167mm	500mm	2	Black Grey	RAL 7021
25230-226	34U	1567mm	500mm	2	Black Grey	RAL 7021
25230-227	38U	1745mm	500mm	2	Black Grey	RAL 7021
25230-228	43U	1967mm	500mm	2	Black Grey	RAL 7021
25230-229	47U	2145mm	500mm	2	Black Grey	RAL 7021
25230-272	12U	531mm	600mm	2	Black Grey	RAL 7021
25230-273	16U	709mm	600mm	2	Black Grey	RAL 7021
25230-274	20U	945mm	600mm	2	Black Grey	RAL 7021
25230-275	25U	1167mm	600mm	2	Black Grey	RAL 7021

CatalogNumber	Rack Height	Height	Depth	Package Quantity	Color	Color Code
25230-276	34U	1567mm	600mm	2	Black Grey	RAL 7021
25230-277	38U	1745mm	600mm	2	Black Grey	RAL 7021
25230-278	43U	1967mm	600mm	2	Black Grey	RAL 7021
25230-279	47U	2145mm	600mm	2	Black Grey	RAL 7021
25230-322		531mm	800mm	2	Black Grey	RAL 7021
25230-323	16U	709mm	800mm	2	Black Grey	RAL 7021
25230-324	20U	945mm	800mm	2	Black Grey	RAL 7021
25230-325	25U	1167mm	800mm	2	Black Grey	RAL 7021
25230-326	34U	1567mm	800mm	2	Black Grey	RAL 7021
25230-327	38U	1745mm	800mm	2	Black Grey	RAL 7021
25230-328	43U	1967mm	800mm	2	Black Grey	RAL 7021
25230-329	47U	2145mm	800mm	2	Black Grey	RAL 7021
26230-040	47U	2087mm	900mm	2	Light Grey	RAL 7035
26230-041	47U	2087mm	1000mm	2	Light Grey	RAL 7035
26230-067	12U	531mm	900mm	2	Light Grey	RAL 7035
26230-068	12U	531mm	1000mm	2	Light Grey	RAL 7035
26230-069	16U	709mm	900mm	2	Light Grey	RAL 7035
26230-080	16U	709mm	1000mm	2	Light Grey	RAL 7035

CatalogNumber	Rack Height	Height	Depth	Package Quantity	Color	Color Code
26230-103	20U	887mm	900mm	2	Light Grey	RAL 7035
26230-104	20U	887mm	1000mm	2	Light Grey	RAL 7035
26230-105	25U	1109mm	900mm	2	Light Grey	RAL 7035
26230-106	25U	1109mm	1000mm	2	Light Grey	RAL 7035
26230-107	34U	1509mm	900mm	2	Light Grey	RAL 7035
26230-108	34U	1509mm	1000mm	2	Light Grey	RAL 7035
26230-109	38U	1687mm	900mm	2	Light Grey	RAL 7035
26230-110	38U	1687mm	1000mm	2	Light Grey	RAL 7035
26230-111	43U	1909mm	900mm	2	Light Grey	RAL 7035
26230-112	43U	1909mm	1000mm	2	Light Grey	RAL 7035
26230-222	12U	531mm	500mm	2	Light Grey	RAL 7035
26230-223	16U	709mm	500mm	2	Light Grey	RAL 7035
26230-224	20U	945mm	500mm	2	Light Grey	RAL 7035
26230-225	25U	1167mm	500mm	2	Light Grey	RAL 7035
26230-226	34U	1567mm	500mm	2	Light Grey	RAL 7035
26230-227	38U	1745mm	500mm	2	Light Grey	RAL 7035
26230-228	43U	1967mm	500mm	2	Light Grey	RAL 7035
26230-229	47U	2145mm	500mm	2	Light Grey	RAL 7035

CatalogNumber	Rack Height	Height	Depth	Package Quantity	Color	Color Code
26230-272	12U	531mm	500mm	2	Light Grey	RAL 7035
26230-273	16U	709mm	600mm	2	Light Grey	RAL 7035
26230-274	20U	945mm	600mm	2	Light Grey	RAL 7035
26230-275	25U	1167mm	600mm	2	Light Grey	RAL 7035
26230-276	34U	1567mm	600mm	2	Light Grey	RAL 7035
26230-277	38U	1745mm	600mm	2	Light Grey	RAL 7035
26230-278	43U	1967mm	600mm	2	Light Grey	RAL 7035
26230-279	47U	2145mm	600mm	2	Light Grey	RAL 7035
26230-322	12U	531mm	800mm	2	Light Grey	RAL 7035
26230-323	16U	709mm	800mm	2	Light Grey	RAL 7035
26230-324	20U	945mm	800mm	2	Light Grey	RAL 7035
26230-325	25U	1167mm	800mm	2	Light Grey	RAL 7035
26230-326	34U	1567mm	800mm	2	Light Grey	RAL 7035
26230-327	38U	1745mm	800mm	2	Light Grey	RAL 7035
26230-328	43U	1967mm	800mm	2	Light Grey	RAL 7035
26230-329	47U	2145mm	800mm	2	Light Grey	RAL 7035
25230-165	29U	1345mm	500mm	2	Black Grey	RAL 7021

Table 2/2

Catalog Number	Finish	Type	Width	Certifications	Quick Ship
----------------	--------	------	-------	----------------	------------

25230-166	Powder Coated	Side Panel	553mm		No
25230-167	Powder Coated	Side Panel	553mm		No
25230-168	Powder Coated	Side Panel	553mm		No
25230-169	Powder Coated	Side Panel	553mm		No
26230-165	Powder Coated	Side Panel	553mm		No
26230-166	Powder Coated	Side Panel	553mm		No
26230-167	Powder Coated	Side Panel	553mm		No
26230-168	Powder Coated	Side Panel	553mm		No
26230-169	Powder Coated	Side Panel	553mm		No
25230-040	Powder Coated	Side Panel		RoHS	No
25230-041	Powder Coated	Side Panel		RoHS	No
25230-067	Powder Coated	Side Panel		RoHS	No
25230-068	Powder Coated	Side Panel		RoHS	No
25230-069	Powder Coated	Side Panel		RoHS	No
25230-080	Powder Coated	Side Panel		RoHS	No
25230-103	Powder Coated	Side Panel		RoHS	No
25230-104	Powder Coated	Side Panel		RoHS	No
25230-105	Powder Coated	Side Panel		RoHS	No
25230-106	Powder Coated	Side Panel		RoHS	No

25230-107	Powder Coated	Side Panel		RoHS	No
25230-108	Powder Coated	Side Panel		RoHS	No
25230-109	Powder Coated	Side Panel		RoHS	No
25230-110	Powder Coated	Side Panel		RoHS	No
25230-111	Powder Coated	Side Panel		RoHS	No
25230-112	Powder Coated	Side Panel		RoHS	No
25230-222	Powder Coated	Side Panel		RoHS	No
25230-223	Powder Coated	Side Panel	553mm	RoHS	No
25230-224	Powder Coated	Side Panel	553mm	RoHS	No
25230-225	Powder Coated	Side Panel	553mm	RoHS	No
25230-226	Powder Coated	Side Panel	553mm	RoHS	No
25230-227	Powder Coated	Side Panel	553mm	RoHS	No
25230-228	Powder Coated	Side Panel	553mm	RoHS	No
25230-229	Powder Coated	Side Panel	553mm	RoHS	No
25230-272	Powder Coated	Side Panel		RoHS	No
25230-273	Powder Coated	Side Panel	553mm	RoHS	No
25230-274	Powder Coated	Side Panel	553mm	RoHS	No
25230-275	Powder Coated	Side Panel	553mm	RoHS	No
25230-276	Powder Coated	Side Panel	553mm	RoHS	No

25230-277	Powder Coated	Side Panel	553mm	RoHS	No
25230-278	Powder Coated	Side Panel	553mm	RoHS	No
25230-279	Powder Coated	Side Panel	553mm	RoHS	No
25230-322	Powder Coated	Side Panel		RoHS	No
25230-323	Powder Coated	Side Panel	553mm	RoHS	No
25230-324	Powder Coated	Side Panel	553mm	RoHS	No
25230-325	Powder Coated	Side Panel	553mm	RoHS	No
25230-326	Powder Coated	Side Panel	553mm	RoHS	No
25230-327	Powder Coated	Side Panel	553mm	RoHS	No
25230-328	Powder Coated	Side Panel	553mm	RoHS	No
25230-329	Powder Coated	Side Panel	553mm	RoHS	No
26230-040	Powder Coated	Side Panel		RoHS	No
26230-041	Powder Coated	Side Panel		RoHS	No
26230-067	Powder Coated	Side Panel		RoHS	No
26230-068	Powder Coated	Side Panel		RoHS	No
26230-069	Powder Coated	Side Panel		RoHS	No
26230-080	Powder Coated	Side Panel		RoHS	No
26230-103	Powder Coated	Side Panel		RoHS	No
26230-104	Powder Coated	Side Panel		RoHS	No

26230-105	Powder Coated	Side Panel		RoHS	No
26230-106	Powder Coated	Side Panel		RoHS	No
26230-107	Powder Coated	Side Panel		RoHS	No
26230-108	Powder Coated	Side Panel		RoHS	No
26230-109	Powder Coated	Side Panel		RoHS	No
26230-110	Powder Coated	Side Panel		RoHS	No
26230-111	Powder Coated	Side Panel		RoHS	No
26230-112	Powder Coated	Side Panel		RoHS	No
26230-222	Powder Coated	Side Panel		RoHS	No
26230-223	Powder Coated	Side Panel	553mm	RoHS	No
26230-224	Powder Coated	Side Panel	553mm	RoHS	No
26230-225	Powder Coated	Side Panel	553mm	RoHS	No
26230-226	Powder Coated	Side Panel	553mm	RoHS	No
26230-227	Powder Coated	Side Panel	553mm	RoHS	No
26230-228	Powder Coated	Side Panel	553mm	RoHS	No
26230-229	Powder Coated	Side Panel	553mm	RoHS	No
26230-272	Powder Coated	Side Panel		RoHS	No
26230-273	Powder Coated	Side Panel	553mm	RoHS	No
26230-274	Powder Coated	Side Panel	553mm	RoHS	No

26230-275	Powder Coated	Side Panel	553mm	RoHS	No
26230-276	Powder Coated	Side Panel	553mm	RoHS	No
26230-277	Powder Coated	Side Panel	553mm	RoHS	No
26230-278	Powder Coated	Side Panel	553mm	RoHS	No
26230-279	Powder Coated	Side Panel	553mm	RoHS	No
26230-322	Powder Coated	Side Panel		RoHS	No
26230-323	Powder Coated	Side Panel	553mm	RoHS	No
26230-324	Powder Coated	Side Panel	553mm	RoHS	No
26230-325	Powder Coated	Side Panel	553mm	RoHS	No
26230-326	Powder Coated	Side Panel	553mm	RoHS	No
26230-327	Powder Coated	Side Panel	553mm	RoHS	No
26230-328	Powder Coated	Side Panel	553mm	RoHS	No
26230-329	Powder Coated	Side Panel	553mm	RoHS	No
25230-165	Powder Coated	Side Panel	553mm		No

ADDITIONAL PRODUCT DETAILS

Optionally the quarter-turn fastener can be fitted with a side panel lock.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE