


3000 U-Channel

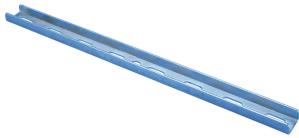

FEATURES

Medium duty U-channel for use with 3000 series beam clamps

SPECIFICATIONS

Finish: Electrogalvanized

Material: Steel

Table 1/2


Catalog Number	Article Number	Length (L)	Height (H)	Width (W)	Thickness (T)	Hole Size (HS)
3003EG	570580	500mm	15 mm	30 mm	2.5 mm	13 mm
3002EG	570570	400mm	15 mm	30 mm	2.5 mm	13 mm
3004EG	570590	600mm	15 mm	30 mm	2.5 mm	13 mm

Table 2/2

Catalog Number	Article Number	X	A	B
3003EG	570580	10.5 x 25 mm	31.5 mm	25 mm
3002EG	570570	10.5 x 25 mm	31.5 mm	25 mm

Catalog Number	Article Number	X	A	B
3004EG	570590	10.5 x 25 mm	31.5 mm	25 mm

 DIAGRAMS



WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

