

310M Universal Beam Clamp, Thick Flange



CERTIFICATIONS



FEATURES

Universal beam clamp for thick beams

SPECIFICATIONS

Material: Cast Iron

Finish: Electrogalvanized

Table 1/2

Catalog Number	Article Number	Hole Size (HS)	Hole Type	Flange Thickness (FT)	A	Torque (TQ)
31011MM	598501	11 mm	Plain	31.8 mm Max	28.6 mm	7 N·m
310M10	389890	10 mm	Threaded	31.8 mm Max	28.6 mm	7 N·m
310M12	388890	12 mm	Threaded	31.8 mm Max	28.6 mm	15 N·m


Table 2/2

Catalog Number	Article Number	Static Load 1 (F1)	Static Load 2 (F2)	Certifications
31011MM	598501	2200N	1100N	FM Approved, Pipe Hanger Components, VdS G4080038
310M10	389890	2200N	1100N	UL, FM Approved, Pipe Hanger Components, cUL, VdS G4080038, ITB
310M12	388890	4200N	3300N	ITB, UL, FM Approved, Pipe Hanger Components, cUL, VdS G4080038

ADDITIONAL PRODUCT DETAILS

Setscrew must be tightened and torqued onto the sloped side of the I-beam.

DIAGRAMS

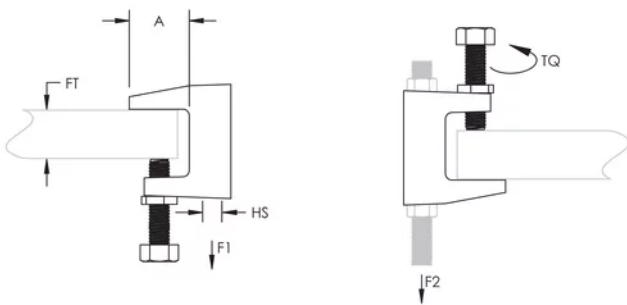

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

