

# nVent CADDY Macrofix Plus



## CERTIFICATIONS



## FEATURES

Includes easy closing mechanism

Age-resistant lining

Combo head bolt works with slotted, hex, or Phillips drivers

Category II noise reduction according to DIN EN ISO 3822-1

Compliant for sound insulation design according to DIN 4109

Reaction-to-fire classification is "E" in compliance with DIN EN 13501-1

## SPECIFICATIONS

<b>Temperature:</b>	-50 to 110 °C
<b>Color:</b>	Black
<b>Finish:</b>	Electrogalvanized
<b>Material:</b>	Steel;EPDM-SBR Rubber

Table 1/2

Catalog Number	Article Number	Outer Diameter (OD)	NB/DN	Rod Size (RS)	Width (W)	Thickness (T)
----------------	----------------	---------------------	-------	---------------	-----------	---------------


MPD014	400078	12 - 14 mm	8	M8, M10	20 mm	1.5 mm
MPD073	400088	70 - 73 mm		M8, M10	20 mm	2 mm
MPD169	400099	165 - 169 mm	150	M8, M10	23 mm	2.5 mm

Table 2/2				
Catalog Number	Article Number	Screw Diameter (Sc)	Screw Length (L)	Static Load
MPD014	400078	6	20mm	1000N
MPD073	400088	6	25mm	1300N
MPD169	400099	8	30mm	2200N

### ADDITIONAL PRODUCT DETAILS

Lining is EPDM rubber.

### DIAGRAMS

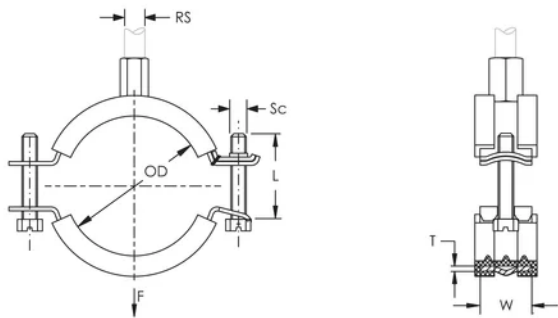

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

