
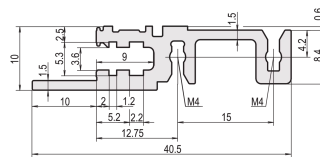


Horizontal Rail, Front, Type H-LD, Heavy, Long Lip, for IEEE Application, 28 HP

CATALOG NUMBER

34560-328

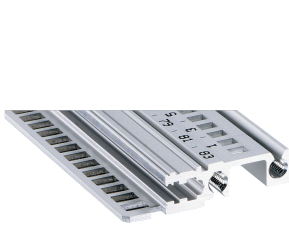

Combinations of horizontal rails and side panels

		+ "can be combined."		+ "combination not recommended"	
Support # 8		-	reference to double side panel	reference to double side panel	reference to double side panel
		+	+	+	+
Support # 1		+	reference to double side panel	reference to double side panel	reference to double side panel
		+	+	+	+
Horizontal rail		+	reference to double side panel	reference to double side panel	reference to double side panel
		+	+	+	+
Side panel		+	reference to double side panel	reference to double side panel	reference to double side panel
		+	+	+	+
Support # 1		+	reference to double side panel	reference to double side panel	reference to double side panel
		+	+	+	+
Support # 8		+	reference to double side panel	reference to double side panel	reference to double side panel
		+	+	+	+

© 2013, Penta GmbH

The horizontal rail with a long lip enables the use of IEEE insertion / extraction handles.

CERTIFICATIONS



FEATURES

For plug-in units with IEEE handle

Long lip (H-LD)

Installation at top and bottom

For CPCI and VME64x systems

Aluminum extrusion, anodized finish, conductive contact surface

PRODUCT ATTRIBUTES

Rack Width: 28HP

Package Quantity: 1

Finish: Anodized

Length: 147.32mm

Material: Aluminum

Product Family: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO

Product Type: Horizontal Rail

Type: Heavy, LD

Works With: Subracks; Cases

ADDITIONAL PRODUCT DETAILS

Delivery is in standard pack multiples. Pricing is per individual item.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE