


Novastar Perforated Steel Door

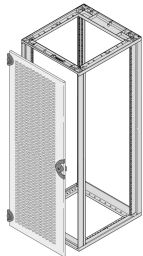

Perforated doors allow 60 % ventilation thus allowing better passive cooling. Novastar perforated doors come with 180° opening angle and aesthetic looks.

CERTIFICATIONS



FEATURES

Can be mounted at front and rear

Perforated (60 % ventilation opening)

Opening angle 180°

Lock with key (2233X)

SPECIFICATIONS

Product Type: Cabinet Door

Material: Steel

Table 1/2

Catalog Number	Rack Height	Height	Width	Package Quantity	Color	Color Code
25230-081	6U	288.4mm	553mm	1	Black Grey	RAL 7021
25230-082	9U	421.75mm	553mm	1	Black Grey	RAL 7021

CatalogNumber	Rack Height	Height	Width	Package Quantity	Color	Color Code
25230-083	12U	555.1mm	553mm	1	Black Grey	RAL 7021
25230-084	16U	732.9mm	553mm	1	Black Grey	RAL 7021
25230-085	20U	910.7mm	553mm	1	Black Grey	RAL 7021
25230-086	25U	1132.95mm	553mm	1	Black Grey	RAL 7021
25230-087	34U	1533mm	553mm	1	Black Grey	RAL 7021
25230-088	38U	1710.8mm	553mm	1	Black Grey	RAL 7021
25230-089	43U	1933.05mm	553mm	1	Black Grey	RAL 7021
25230-090	47U	2110.85mm	553mm	1	Black Grey	RAL 7021
25230-091	29U	1310.75mm	553mm	1	Black Grey	RAL 7021
26230-081	6U	288.4mm	553mm	1	Light Grey	RAL 7035
26230-082	9U	421.75mm	553mm	1	Light Grey	RAL 7035
26230-083	12U	555.1mm	553mm	1	Light Grey	RAL 7035
26230-084	16U	732.9mm	553mm	1	Light Grey	RAL 7035
26230-085	20U	910.7mm	553mm	1	Light Grey	RAL 7035
26230-086	25U	1132.95mm	553mm	1	Light Grey	RAL 7035
26230-087	34U	1533mm	553mm	1	Light Grey	RAL 7035
26230-088	38U	1710.8mm	553mm	1	Light Grey	RAL 7035
26230-089	43U	1933.05mm	553mm	1	Light Grey	RAL 7035

CatalogNumber	Rack Height	Height	Width	Package Quantity	Color	Color Code
26230-090	47U	2110.85mm	553mm	1	Light Grey	RAL 7035
26230-091	29U	1310.75mm	553mm	1	Light Grey	RAL 7035

Table 2/2

Catalog Number	Finish	Type	Quick Ship
25230-081	Powder Coated	Steel Door, Perforated	No
25230-082	Powder Coated	Steel Door, Perforated	No
25230-083	Powder Coated	Steel Door, Perforated	No
25230-084	Powder Coated	Steel Door, Perforated	No
25230-085	Powder Coated	Steel Door, Perforated	No
25230-086	Powder Coated	Steel Door, Perforated	No
25230-087	Powder Coated	Steel Door, Perforated	No
25230-088	Powder Coated	Steel Door, Perforated	No
25230-089	Powder Coated	Steel Door, Perforated	No
25230-090	Powder Coated	Steel Door, Perforated	No
25230-091	Powder Coated	Steel Door, Perforated	No
26230-081	Powder Coated	Steel Door, Perforated	No
26230-082	Powder Coated	Steel Door, Perforated	No
26230-083	Powder Coated	Steel Door, Perforated	No
26230-084	Powder Coated	Steel Door, Perforated	No

Catalog Number	Finish	Type	Quick Ship
26230-085	Powder Coated	Steel Door, Perforated	No
26230-086	Powder Coated	Steel Door, Perforated	No
26230-087	Powder Coated	Steel Door, Perforated	No
26230-088	Powder Coated	Steel Door, Perforated	No
26230-089	Powder Coated	Steel Door, Perforated	No
26230-090	Powder Coated	Steel Door, Perforated	No
26230-091	Powder Coated	Steel Door, Perforated	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE