


Plug-In Unit U-Profile Front Panel for XL Handle

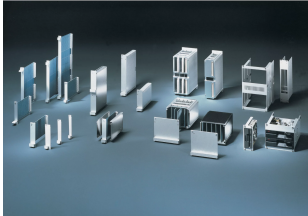

Front panel for XL handle. Shieldable with textile gasket. with or without cutout for a microswitch.

CERTIFICATIONS



FEATURES

Al, front anodized, sides and rear conductive

Suitable for sleeve and collar screw

U-front profile, shieldable, for inserter/extractor handle, type XL

SPECIFICATIONS

Material:	Aluminum
Finish:	Anodized; Passivated
Accessory Type:	Front panel
Product Type:	Front Panel
Type:	Front Panel for Handle (PIU)
EMC Shielding:	No (Retrofittable)

Table 1/3

Catalog Number	Rack Width	Package Quantity	Handle Type	Mounting	Front Finish	Rear Finish
30849-153	4HP	1	XL	Screw-on Front	Anodized	Conductive

CatalogNumber	Rack Width	Package Quantity	Handle Type	Mounting	Front Finish	Rear Finish
30849-154	4HP	1	XL	Screw-on Front	Anodized	Conductive
30849-156	8HP	1	XL	Screw-on Front	Anodized	Conductive
30849-155	8HP	1	XL	Screw-on Front	Anodized	Conductive
30849-158	12HP	1	XL	Screw-on Front	Anodized	Conductive
30849-157	12HP	1	XL	Screw-on Front	Anodized	Conductive

Table 2/3

Catalog Number	Treated Edges	Complies With	Depth (D)	Height (H)	Rack Height	Width (W)
30849-153	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U	20mm
30849-154	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U	20mm
30849-156	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U	40.3mm
30849-155	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U	40.3mm
30849-158	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U	60.6mm
30849-157	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U	60.6mm

Table 3/3

Catalog Number	Quick Ship
30849-153	No
30849-154	No
30849-156	No


Catalog Number	Quick Ship
30849-155	No
30849-158	No
30849-157	No

ADDITIONAL PRODUCT DETAILS

Delivery is exclusively in standard pack quantity, Please order EMC textile gasket and microswitch separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

DIAGRAMS

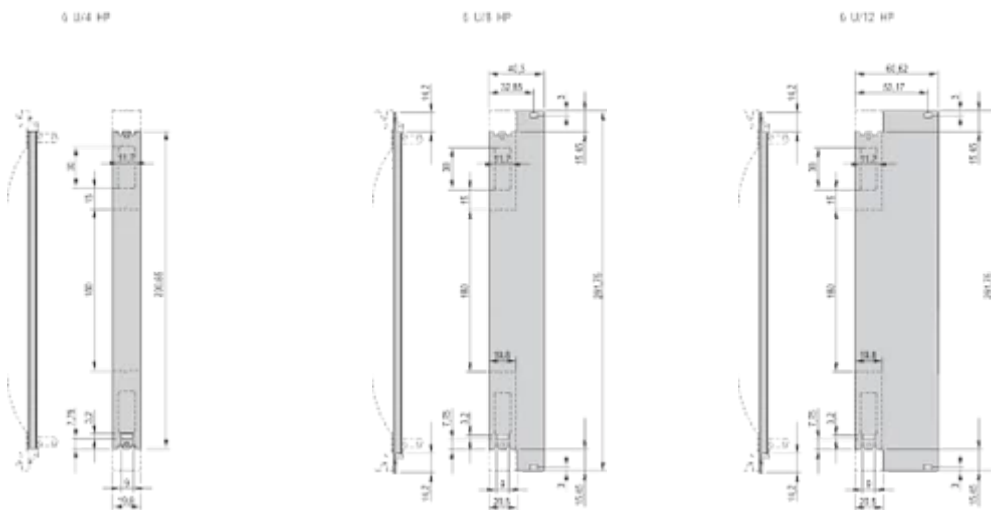

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE