

Oval Pipe Clamp with Nut, DN20, M8, M10 Rod

CATALOG NUMBER

MXOVDN20EG



FEATURES

Designed to support pre-insulated twin tubes and integrated power cable for solar heat collectors

Shape of clamp provides a stable attachment to wall or ceiling

PRODUCT ATTRIBUTES

Article Number: 401246

Material: Steel

Finish: Electrogalvanized

NB/DN: 20

Rod Size (RS): M8;M10

A: 58 mm

B: 108 mm


Width (W): 20 mm

Thickness (T): 2 mm

Screw Diameter (Sc): 6

Screw Length (L): 20mm

DIAGRAMS

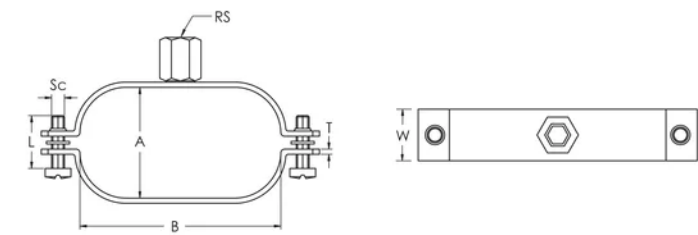

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

