

# nVent ERIFLEX Flexbus Transformer Cover IP2X for 2 Conductors per Phase

## Data Solutions



### CERTIFICATIONS



### FEATURES

Input/output for neutral/ground conductor

Resistance to solvent and hydrocarbon splashes

Installs quickly and easily

UV resistance

### SPECIFICATIONS


Table 1/2

| Catalog Number     | Article Number | Material          | Working Temperature | Length (L) | Width (W) | Depth (D) |
|--------------------|----------------|-------------------|---------------------|------------|-----------|-----------|
| FLEXCOVIP2XT<br>WO | 508161         | Polyvinylchloride | -40 to 140°C        | 670mm      | 230mm     | 180mm     |

Table 2/2

| Catalog Number | Article Number | Unit Weight |
|----------------|----------------|-------------|
| FLEXCOVIP2XTWO | 508161         | 0.84kg      |

## DIAGRAMS

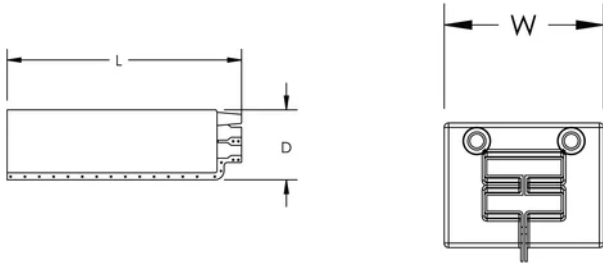

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**