

AMC Front Panel With Pull Handle



AdvancedMC Front Panel including EMC gasket for AMC.0 Rev. 2.0 Modules.

CERTIFICATIONS



FEATURES

In accordance with AMC.0 R2.0 specification

Front panel for pull-handle mechanism (with cut-outs for light pipe)

For the use together with the AMC Pull-handle mechanism, AMC.0 R2.0

SPECIFICATIONS

Accessory Type: Front panel

Product Type: Front Panel


Table 1/2

Catalog Number	Height (H)	Rack Width	Design Feature	Material	Finish	Package Quantity
30849-682	73.8mm	6HP	Full-Size	Aluminum	Passivated	1
30849-670	148.8mm	4HP		Aluminum	Passivated	1
30849-694	148.8mm	6HP	Full-Size	Aluminum	Passivated	1

CatalogNumber	Height (H)	Rack Width	Design Feature	Material	Finish	Package Quantity
30849-403	73.8mm	4HP	Mid-Size	Stainless Steel		1
30849-404	73.8mm	6HP	Full-Size	Stainless Steel		1
30849-406	148.8mm	4HP	Mid-Size	Stainless Steel		1
30849-407	148.8mm	6HP	Full-Size	Stainless Steel		1
30849-402	73.8mm	3HP	Compact	Stainless Steel		1
30849-658	73.8mm	4HP	Mid-Size	Aluminum	Passivated	1

Table 2/2

Catalog Number	Front Finish	Rear Finish	Depth (D)	Width (W)	Quick Ship
30849-682	Raw	Raw	2.5mm	29mm	No
30849-670	Raw	Raw	2.5mm	19mm	No
30849-694	Raw	Raw	2.5mm	29mm	No
30849-403	Raw	Raw	1mm	19mm	No
30849-404	Raw	Raw	1mm	29mm	No
30849-406	Raw	Raw	1mm	19mm	No
30849-407	Raw	Raw	1mm	29mm	No
30849-402	Raw	Raw	1mm	13.9mm	No
30849-658	Raw	Raw	2.5mm	19mm	No

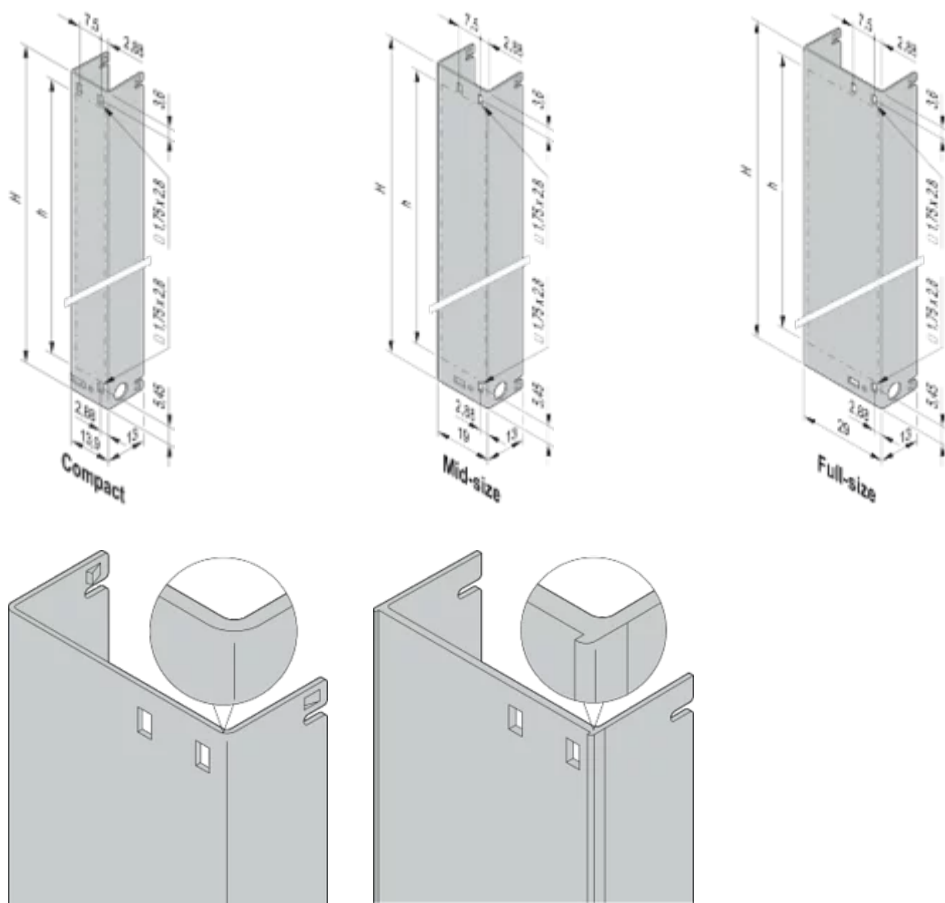

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE