


# Die Cast Foot

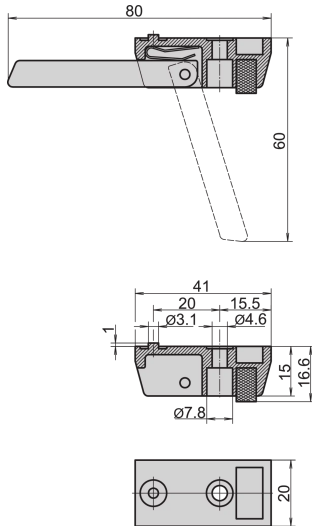

The tip-up feet from aluminum die cast material enable mounting on the bottom plate of a case. Available with or without tip-up function. Color RAL 9006 White Aluminum.

## CERTIFICATIONS



## FEATURES

Positioning of case is secured by anti-slip rubber inserts

Can be used instead of standard feet

Load-carrying capacity: 50 kg per foot, max case weight 40 kg

Mounting holes are provided in bottom cover of the cases

## SPECIFICATIONS

|                        |                                                           |
|------------------------|-----------------------------------------------------------|
| <b>Material:</b>       | Aluminum                                                  |
| <b>Works With:</b>     | Cases                                                     |
| <b>Product Family:</b> | RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO; Inpac |
| <b>Product Type:</b>   | Foot                                                      |
| <b>Color:</b>          | Silver                                                    |

Table 1/1

| Catalog Number | Package Quantity | Color Code | Type                 | Quick Ship |
|----------------|------------------|------------|----------------------|------------|
| 10603-001      | 1                | RAL 9006   | Foot, Without Tip-up | No         |
| 10603-002      | 1                | RAL 9006   | Foot, With Tip-up    | No         |

## ADDITIONAL PRODUCT DETAILS

Delivery is in standard pack multiples. Pricing is per individual item.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**