

HW Wedge Nut for Dovetail Deck



FEATURES

Trapeze nut for hanging threaded rod from steel ceilings

Installs easily

Fits several composite floor decking profiles

SPECIFICATIONS

Finish: Electrogalvanized

Material: Steel

Table 1/2

Catalog Number	Article Number	Rod Size (RS)	Angle (a)	A	B	C
PHWC8	196250	8	25 °	18 mm	9.5 mm	9.5 mm
PHWC6	196240	6	25 °	18 mm	9.5 mm	9.5 mm
HW10SR	188820	10	12 °	21 mm	13 mm	10 mm
HW4	187260	4	15 °	25 mm	12 mm	12 mm
HW6	187270	6	15 °	25 mm	12 mm	12 mm


CatalogNumber	Article Number	Rod Size (RS)	Angle (a)	A	B	C
HW8	187280	8	15 °	25 mm	12 mm	12 mm
HW10	187290	10	15 °	25 mm	12 mm	12 mm
HW12	187300	12	15 °	25 mm	16 mm	16 mm

Table 2/2

Catalog Number	Article Number	Static Load
PHWC8	196250	1700N
PHWC6	196240	1200N
HW10SR	188820	2100N
HW4	187260	
HW6	187270	1200N
HW8	187280	1700N
HW10	187290	2100N
HW12	187300	2100N

Metal Decking Compatibility for Wedge Nuts								
Part Number		HW4	HW6	HW8	HW10	HW12	PHWC6	PHWC8
TATA	Comflor 51+	X	X	X	X	X		
	Comflor 60/75						X	X
	Comflor 80/95						X	X
	Ribdeck 80						X	X
SMD	R51+	X	X	X	X	X		
KINGSPAN	Multideck 50	X	X	X	X	X		
CMF	Metfloor 55	X	X	X	X	X		

DIAGRAMS

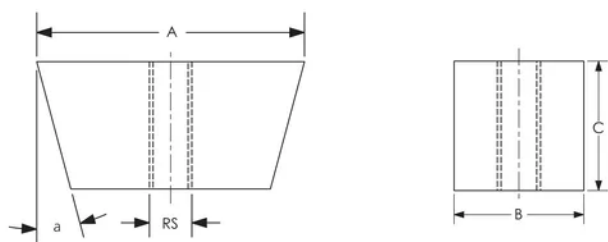

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

