


# nVent CADDY Macrofix Plus Kombi with Combination Nut

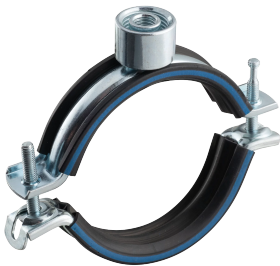

## FEATURES

Includes easy closing mechanism

Age-resistant lining

Category II noise reduction according to DIN EN ISO 3822-1

Compliant for sound insulation design according to DIN 4109

Reaction-to-fire classification is "E" in compliance with DIN EN 13501-1

## SPECIFICATIONS

<b>Rod Size (RS):</b>	M8;M10;1/2"
<b>Temperature:</b>	-50 to 110 °C
<b>Color:</b>	Black
<b>Finish:</b>	Electrogalvanized
<b>Material:</b>	Steel;EPDM-SBR Rubber

Table 1/2

Catalog Number	Article Number	Outer Diameter (OD)	NB/DN	Width (W)	Thickness (T)	Screw Diameter (Sc)
MPK037	586755	31 - 37 mm	25	20 mm	1 mm	6 mm
MPK031	586754	25 - 31 mm	20	20 mm	1 mm	6 mm

CatalogNumber	Article Number	Outer Diameter (OD)	NB/DN	Width (W)	Thickness (T)	ScrewDiameter (Sc)
MPK044	586756	37 - 44 mm	32	20 mm	1 mm	6 mm
MPK051	586757	45 - 51 mm	40	21 mm	1.25 mm	6 mm
MPK068	586759	58 - 68 mm	50	21 mm	1.25 mm	6 mm
MPK058	586758	50 - 58 mm		21 mm	1.25 mm	6 mm
MPK078	586760	68 - 78 mm	65	23 mm	1.5 mm	6 mm
MPK088	586761	78 - 88 mm		23 mm	1.5 mm	6 mm
MPK098	586762	88 - 98 mm	80	23 mm	1.75 mm	6 mm
MPK118	586763	108 - 118 mm	100	23 mm	1.75 mm	6 mm
MPK170	586767	160 - 170 mm	150	25 mm	2 mm	6 mm
MPK148	586765	138 - 148 mm	125	25 mm	2 mm	6 mm
MPK160	586766	150 - 160 mm		25 mm	2 mm	6 mm
MPK138	586764	128 - 138 mm		23 mm	2 mm	6 mm
MPK201	586768	190 - 200 mm		27 mm	2.25 mm	6 mm

Table 2/2


Catalog Number	Article Number	Screw Length (L)	Static Load	Unit Weight
MPK037	586755	32mm	1000N	0.12 kg
MPK031	586754	32mm	1000N	0.11 kg
MPK044	586756	37mm	1000N	0.12 kg
MPK051	586757	37mm	1500N	0.14 kg

Catalog Number	Article Number	Screw Length (L)	Static Load	Unit Weight
MPK068	586759	40mm	1500N	0.16 kg
MPK058	586758	37mm	1500N	0.15 kg
MPK078	586760	40mm	2000N	0.19 kg
MPK088	586761	40mm	2000N	0.2 kg
MPK098	586762	45mm	2500N	0.27 kg
MPK118	586763	50mm	2500N	0.3 kg
MPK170	586767	50mm	3200N	0.42 kg
MPK148	586765	50mm	3200N	0.4 kg
MPK160	586766	50mm	3200N	0.42 kg
MPK138	586764	50mm	3000N	0.34 kg
MPK201	586768	50mm	3600N	0.63 kg

## ADDITIONAL PRODUCT DETAILS

Lining is EPDM rubber.

## DIAGRAMS

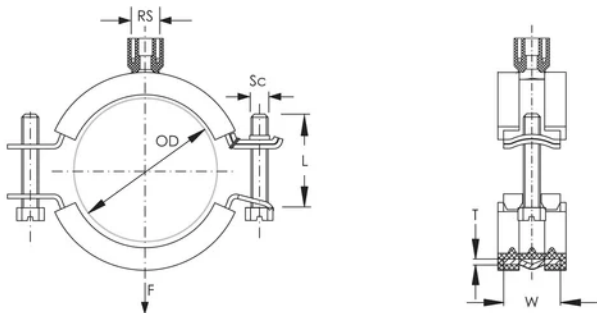

**WARNING**

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

**Europe**

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

**Europe**

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

**APAC**

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**

