

PESHTS Heavy Duty Pipe Slide with Strap, Two Connectors



FEATURES

For use with two pipe clamps


Includes welded on mounting strap

SPECIFICATIONS

Catalog Number	PESHTS
Article Number	580567
Material	Steel
Finish	Electrogalvanized
Rod Size (RS)	M12 M16
Height (H)	57 mm
Length (L)	275mm
Δ Length (ΔL)	245 mm
Width (W)	188 mm
A	160 mm
B	40 mm
C	210 mm
X	13 x 25 mm

Catalog Number	PESHTS
Temperature	240 °C Max
Static Load 1 (F1)	9000N
Static Load 2 (F2)	5000N

DIAGRAMS

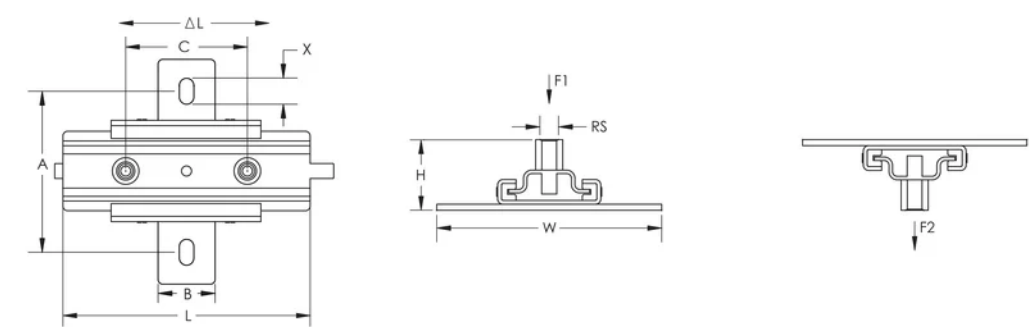

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

