


# Joint Bond Mold Pair with Mounting Parts and Clips, Signal

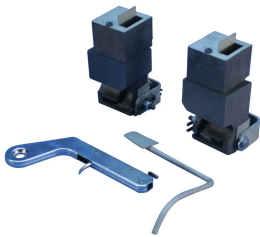

## FEATURES

Pair of replacement molds with mounting parts designed for the installation of jumper bonds to the head of the rail

Connection is made within the confines of the splice bar

Includes mold cleaner and flint ignitor

## SPECIFICATIONS

**Rail Type:** 85 lb to 141 lb T-Rail Sections

**Material:** Steel;Graphite

**Product:** Mold, frames, and clips

Table 1/1

| Catalog Number | Article Number | Bond Terminal Style | Conductor Size   | Conductor Outer Diameter, Nominal | Welder Style |
|----------------|----------------|---------------------|------------------|-----------------------------------|--------------|
| SBM456F        |                | 3/4" XS             | 3/16" Bondstrand | 4.76mm                            | T6, T7       |
| SBS925F        |                | Head Free           | 3/16" Bondstrand | 4.76mm                            | T6, T7       |
| SBS5838F       | 165171         | 3/4" Tab            | 3/16" Bondstrand | 4.76mm                            | T6, T7       |
| SBS898F        |                | 1" Tab              | 5/16" Bondstrand | 7.94mm                            | T6, T7       |

**WARNING**

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**⚠ WARNING:** This product can expose you to chemicals including diisononyl phthalate, which is known to the State of California to cause cancer. For more information go to [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov).

**North America**

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

**Europe**

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

**Europe**

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

**APAC**

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**