

FC nVent ERIFLEX Flexibar to Busbar Clamp, 80 mm Busbar Width, 20–24 mm

CATALOG NUMBER

FC80X24



CERTIFICATIONS



FEATURES

Connects nVent ERIFLEX Flexibar to copper busbar

Two plates complete with screws

Allows for excellent electrical contact

Installs quickly and easily

Ideal for on site modifications

RoHS compliant

PRODUCT ATTRIBUTES

Article Number: 553050

Material: Steel

Finish: Electrogalvanized

Quality Class: 8.8

Clamping Capacity: 20mm

Busbar Width: 80 mm

Conductor Width: 20 - 24 mm

Height (H): 105 mm

Width (W): 52 mm

A: 36 mm


B: 90 mm

Screw Diameter (Sc): 8

Torque (TQ): 10 N·m

Unit Weight: 0.43 kg

DIAGRAMS

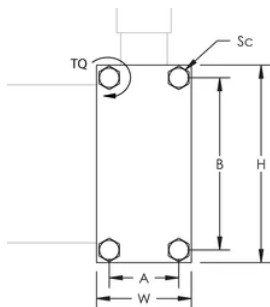

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE