

Coaxial Surge Protector



CERTIFICATIONS



FEATURES

Simple plug-in installation

Supplied with mounting bracket and ground lug terminal

Low insertion and return loss

Wide operating frequency spectrum

SPECIFICATIONS

Capacitance:	1.5 pF
Insulation Resistance:	10
Max Discharge Current (Imax), Per Mode:	20kA 8/20 μ s
Impulse Life:	400 @ 500 A 10/1000 μ s
Frequency:	0 - 3 GHz
Enclosure Rating:	IP 20;NEMA®-1
Enclosure Material:	Metal
Temperature:	-40 to 90 °C

Table 1/2


Catalog Number	Max Ground Terminal Wire Size	Connection Type	Spark-Over Voltage @ 100 V/ μ s	Spark-Over Voltage @ 100 V/s	Depth (D)	Height (H)
CSP1BNC600	2.5mm ²	BNC, Male/Female	1100 V	480 - 720 V	25.4mm	25 mm
CSP1BNC90	2.5mm ²	BNC, Male/Female	450 V	72 - 108 V	25.4mm	25 mm
CSP1F600	2.5mm ²	F-Type, Male/Female	1100 V	480 - 720 V	25.4mm	25 mm
CSP1F90	2.5mm ²	F-Type, Male/Female	450 V	72 - 108 V	25.4mm	25 mm
CSP1NB600	2.5mm ²	N-Type, Female/Female	1100 V	480 - 720 V	25.4mm	25 mm
CSP1NB90	2.5mm ²	N-Type, Female/Female	450 V	72 - 108 V	25.4mm	25 mm
CSP1NBM600	2.5mm ²	N-Bulkhead, Male/Female	1100 V	480 - 720 V	25.4mm	25 mm
CSP1NBM90	2.5mm ²	N-Bulkhead, Male/Female	450 V	72 - 108 V	25.4mm	25 mm
CSP1NMF600	2.5mm ²	N-Type, Male/Female	1100 V	480 - 720 V	25.4mm	25 mm
CSP1NMF90	2.5mm ²	N-Type, Male/Female	450 V	72 - 108 V	25.4mm	25 mm
CSP1SMA600	2.5mm ²	SMA, Male/Female	1100 V	480 - 720 V	25.4mm	25 mm
CSP1SMA90	2.5mm ²	SMA, Male/Female	450 V	72 - 108 V	25.4mm	25 mm

Table 2/2

Catalog Number	Width (W)	Unit Weight
CSP1BNC600	25 mm	0.13 kg
CSP1BNC90	25 mm	0.13 kg
CSP1F600	25 mm	0.13 kg
CSP1F90	25 mm	0.13 kg

Catalog Number	Width (W)	Unit Weight
CSP1NB600	25 mm	0.13 kg
CSP1NB90	25 mm	0.13 kg
CSP1NBM600	25 mm	0.13 kg
CSP1NBM90	25 mm	0.13 kg
CSP1NMF600	25 mm	0.13 kg
CSP1NMF90	25 mm	0.13 kg
CSP1SMA600	25 mm	0.13 kg
CSP1SMA90	25 mm	0.13 kg

DIAGRAMS

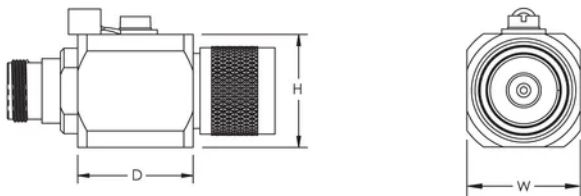

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE