


## Inner Door, UID

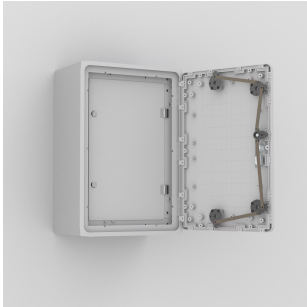

Displays and indicators can be mounted on a surface within the enclosure while covering other components, and preventing unauthorized access.

### FEATURES

Description: For controls, meters, lamps, etc. Hinges can be mounted to allow left or right hand opening. Lock double-bit 3 mm insert. Distance between UID and enclosure door: 48 mm.

Material: Glass fibre reinforced polyester.

Finish: RAL 7035.

Protection: IP 20.

Delivery: 1 piece with mounting accessories.

A plain door to be mounted inside a wall mounted enclosure

Additional mounting surface providing two levels of access

Non authorized personnel have access to the controls on the inner door only

This accessory is often used in enclosures with glazed door

SPECIFICATIONS

- Material:

Glass Fiber Reinforced Polymer
- Color:

Light Gray
- Color Code:

RAL 7035
- Finish:

Smooth Matte

| Table 1/1      |        |       |            |
|----------------|--------|-------|------------|
| Catalog Number | Height | Width | Quick Ship |
| UID5050        | 500mm  | 500mm | No         |
| UID5075        | 500mm  | 750mm | No         |
| UID10050       | 1000mm | 500mm | No         |
| UID7550        | 750mm  | 500mm | No         |
| UID7575        | 750mm  | 750mm | No         |
| UID10075       | 1000mm | 750mm | No         |

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE