

# 19" Front Panel

Front panels made of Aluminum.



## CERTIFICATIONS



## FEATURES

Aluminum, 4 or 3 mm thick, with Anodized or Painted finish

## SPECIFICATIONS

|                        |             |
|------------------------|-------------|
| <b>Rack Width:</b>     | 95HP        |
| <b>Material:</b>       | Aluminum    |
| <b>Accessory Type:</b> | Front panel |
| <b>Product Type:</b>   | Front Panel |

Table 1/3

| Catalog Number | Rack Height | Depth (D) | Mounting       | Finish        | Front Finish | Package Quantity |
|----------------|-------------|-----------|----------------|---------------|--------------|------------------|
| 30219-098      | 1U          | 3mm       | Screw-on Front | Anodized      | Anodized     | 1                |
| 30118-948      | 1U          | 3mm       | Screw-on Front | Powder Coated | Painted      | 1                |
| 30118-299      | 1U          | 3mm       | Screw-on Front | Powder Coated | Painted      | 1                |

| CatalogNumber | Rack Height | Depth (D) | Mounting       | Finish        | Front Finish | Package Quantity |
|---------------|-------------|-----------|----------------|---------------|--------------|------------------|
| 40304-074     | 1U          | 4mm       | Screw-on Front | Anodized      | Anodized     | 1                |
| 30219-101     | 2U          | 3mm       | Screw-on Front | Anodized      | Anodized     | 1                |
| 30118-301     | 2U          | 3mm       | Screw-on Front | Powder Coated | Painted      | 1                |
| 30118-949     | 2U          | 3mm       | Screw-on Front | Powder Coated | Painted      | 1                |
| 40304-075     | 2U          | 4mm       | Screw-on Front | Anodized      | Anodized     | 1                |
| 30219-104     | 3U          | 3mm       | Screw-on Front | Anodized      | Anodized     | 1                |
| 30118-302     | 3U          | 3mm       | Screw-on Front | Powder Coated | Painted      | 1                |
| 30118-950     | 3U          | 3mm       | Screw-on Front | Powder Coated | Painted      | 1                |
| 40304-076     | 3U          | 4mm       | Screw-on Front | Anodized      | Anodized     | 1                |
| 30219-107     | 4U          | 3mm       | Screw-on Front | Anodized      | Anodized     | 1                |
| 30118-303     | 4U          | 3mm       | Screw-on Front | Powder Coated | Painted      | 1                |
| 30118-951     | 4U          | 3mm       | Screw-on Front | Powder Coated | Painted      | 1                |
| 30219-110     | 5U          | 3mm       | Screw-on Front | Powder Coated | Anodized     | 1                |
| 30118-304     | 5U          | 3mm       | Screw-on Front | Powder Coated | Painted      | 1                |
| 30118-952     | 5U          | 3mm       | Screw-on Front | Powder Coated | Painted      | 1                |
| 40304-077     | 4U          | 4mm       | Screw-on Front | Anodized      | Anodized     | 1                |
| 30118-953     | 6U          | 3mm       | Screw-on Front | Powder Coated | Painted      | 1                |
| 30118-305     | 6U          | 3mm       | Screw-on Front | Powder Coated | Painted      | 1                |

| CatalogNumber | Rack Height | Depth (D) | Mounting       | Finish        | Front Finish | Package Quantity |
|---------------|-------------|-----------|----------------|---------------|--------------|------------------|
| 30219-113     | 6U          | 3mm       | Screw-on Front | Anodized      | Anodized     | 1                |
| 40304-079     | 6U          | 4mm       | Screw-on Front | Anodized      | Anodized     | 1                |
| 30118-954     | 7U          | 3mm       | Screw-on Front | Powder Coated | Painted      | 1                |
| 30118-306     | 7U          | 3mm       | Screw-on Front | Powder Coated | Painted      | 1                |
| 30219-137     | 7U          | 3mm       | Screw-on Front | Anodized      | Anodized     | 1                |
| 40304-080     | 7U          | 4mm       | Screw-on Front | Anodized      | Anodized     | 1                |
| 30118-956     | 9U          | 3mm       | Screw-on Front | Powder Coated | Painted      | 1                |
| 30118-308     | 9U          | 3mm       | Screw-on Front | Powder Coated | Painted      | 1                |
| 30219-143     | 9U          | 3mm       | Screw-on Front | Anodized      | Anodized     | 1                |
| 40304-082     | 9U          | 4mm       | Screw-on Front | Anodized      | Anodized     | 1                |
| 30118-307     | 8U          | 3mm       | Screw-on Front | Powder Coated | Painted      | 1                |
| 30118-309     | 10U         | 3mm       | Screw-on Front | Powder Coated | Painted      | 1                |
| 30118-955     | 8U          | 3mm       | Screw-on Front | Powder Coated | Painted      | 1                |
| 30118-957     | 10U         | 3mm       | Screw-on Front | Powder Coated | Painted      | 1                |
| 30219-138     | 8U          | 3mm       | Screw-on Front | Anodized      | Anodized     | 1                |
| 30219-144     | 10U         | 3mm       | Screw-on Front | Anodized      | Anodized     | 1                |
| 40304-078     | 5U          | 4mm       | Screw-on Front | Anodized      | Anodized     | 1                |
| 40304-081     | 8U          | 4mm       | Screw-on Front | Anodized      | Anodized     | 1                |

| CatalogNumber | Rack Height | Depth (D) | Mounting       | Finish   | Front Finish | Package Quantity |
|---------------|-------------|-----------|----------------|----------|--------------|------------------|
| 40304-083     | 10U         | 4mm       | Screw-on Front | Anodized | Anodized     | 1                |

Table 2/3

| Catalog Number | Rear Finish | Treated Edges | Color Code | EMC Shielding | Height (H) | Type            |
|----------------|-------------|---------------|------------|---------------|------------|-----------------|
| 30219-098      | Anodized    | No            |            | No            | 43.6mm     | 19" Front Panel |
| 30118-948      | Painted     |               | RAL 7021   | No            | 43.6mm     | 19" Front Panel |
| 30118-299      | Painted     |               | RAL 7035   | No            | 43.6mm     | 19" Front Panel |
| 40304-074      | Anodized    | Yes           |            | No            | 43.6mm     | 19" Front Panel |
| 30219-101      | Anodized    | No            |            | No            | 88.1mm     | 19" Front Panel |
| 30118-301      | Painted     |               | RAL 7035   | No            | 88.1mm     | 19" Front Panel |
| 30118-949      | Painted     |               | RAL 7021   | No            | 88.1mm     | 19" Front Panel |
| 40304-075      | Anodized    | Yes           |            | No            | 88.1mm     | 19" Front Panel |
| 30219-104      | Anodized    | No            |            | No            | 132.5mm    | 19" Front Panel |
| 30118-302      | Painted     |               | RAL 7035   | No            | 132.5mm    | 19" Front Panel |
| 30118-950      | Painted     |               | RAL 7021   | No            | 132.5mm    | 19" Front Panel |
| 40304-076      | Anodized    | Yes           |            | No            | 132.5mm    | 19" Front Panel |
| 30219-107      | Anodized    | No            |            | No            | 177mm      | 19" Front Panel |
| 30118-303      | Painted     |               | RAL 7035   | No            | 177mm      | 19" Front Panel |
| 30118-951      | Painted     |               | RAL 7021   | No            | 177mm      | 19" Front Panel |

| CatalogNumber | Rear Finish | Treated Edges | Color Code | EMC Shielding | Height (H) | Type            |
|---------------|-------------|---------------|------------|---------------|------------|-----------------|
| 30219-110     | Anodized    | No            |            | No            | 221.4mm    | 19" Front Panel |
| 30118-304     | Painted     |               | RAL 7035   | No            | 221.4mm    | 19" Front Panel |
| 30118-952     | Painted     |               | RAL 7021   | No            | 221.4mm    | 19" Front Panel |
| 40304-077     | Anodized    | Yes           |            | No            | 177mm      | 19" Front Panel |
| 30118-953     | Painted     |               | RAL 7021   | No            | 265.9mm    | 19" Front Panel |
| 30118-305     | Painted     |               | RAL 7035   | No            | 265.9mm    | 19" Front Panel |
| 30219-113     | Anodized    | No            |            | No            | 265.9mm    | 19" Front Panel |
| 40304-079     | Anodized    | Yes           |            | No            | 265.9mm    | 19" Front Panel |
| 30118-954     | Painted     |               | RAL 7021   | No            | 310.3mm    | 19" Front Panel |
| 30118-306     | Painted     |               | RAL 7035   | No            | 310.3mm    | 19" Front Panel |
| 30219-137     | Anodized    | No            |            | No            | 310.3mm    | 19" Front Panel |
| 40304-080     | Anodized    | Yes           |            | No            | 310.3mm    | 19" Front Panel |
| 30118-956     | Painted     |               | RAL 7021   | No            | 399.2mm    | 19" Front Panel |
| 30118-308     | Painted     |               | RAL 7035   | No            | 399.2mm    | 19" Front Panel |
| 30219-143     | Anodized    | No            |            | No            | 399.2mm    | 19" Front Panel |
| 40304-082     | Anodized    | Yes           |            | No            | 399.2mm    | 19" Front Panel |
| 30118-307     | Painted     |               | RAL 7035   | No            | 354.8mm    | 19" Front Panel |
| 30118-309     | Painted     |               | RAL 7035   | No            | 443.7mm    | 19" Front Panel |

| CatalogNumber | Rear Finish | Treated Edges | Color Code | EMC Shielding | Height (H) | Type            |
|---------------|-------------|---------------|------------|---------------|------------|-----------------|
| 30118-955     | Painted     |               | RAL 7021   | No            | 354.8mm    | 19" Front Panel |
| 30118-957     | Painted     |               | RAL 7021   | No            | 443.7mm    | 19" Front Panel |
| 30219-138     | Anodized    | No            |            | No            | 354.8mm    | 19" Front Panel |
| 30219-144     | Anodized    | No            |            | No            | 443.7mm    | 19" Front Panel |
| 40304-078     | Anodized    | Yes           |            | No            | 221.4mm    | 19" Front Panel |
| 40304-081     | Anodized    | Yes           |            | No            | 354.8mm    | 19" Front Panel |
| 40304-083     | Anodized    | Yes           |            | No            | 443.7mm    | 19" Front Panel |

Table 3/3

| Catalog Number | Width (W) | Quick Ship |
|----------------|-----------|------------|
| 30219-098      | 483mm     | No         |
| 30118-948      | 483mm     | No         |
| 30118-299      | 483mm     | No         |
| 40304-074      | 483mm     | No         |
| 30219-101      | 483mm     | No         |
| 30118-301      | 483mm     | No         |
| 30118-949      | 483mm     | No         |
| 40304-075      | 483mm     | No         |
| 30219-104      | 483mm     | No         |
| 30118-302      | 483mm     | No         |


| Catalog Number | Width (W) | Quick Ship |
|----------------|-----------|------------|
| 30118-950      | 483mm     | No         |
| 40304-076      | 483mm     | No         |
| 30219-107      | 483mm     | No         |
| 30118-303      | 483mm     | No         |
| 30118-951      | 483mm     | No         |
| 30219-110      | 483mm     | No         |
| 30118-304      | 483mm     | No         |
| 30118-952      | 483mm     | No         |
| 40304-077      | 483mm     | No         |
| 30118-953      | 483mm     | No         |
| 30118-305      | 483mm     | No         |
| 30219-113      | 483mm     | No         |
| 40304-079      | 483mm     | No         |
| 30118-954      | 483mm     | No         |
| 30118-306      | 483mm     | No         |
| 30219-137      | 483mm     | No         |
| 40304-080      | 483mm     | No         |
| 30118-956      | 483mm     | No         |

| Catalog Number | Width (W) | Quick Ship |
|----------------|-----------|------------|
| 30118-308      | 483mm     | No         |
| 30219-143      | 483mm     | No         |
| 40304-082      | 483mm     | No         |
| 30118-307      | 483mm     | No         |
| 30118-309      | 483mm     | No         |
| 30118-955      | 483mm     | No         |
| 30118-957      | 483mm     | No         |
| 30219-138      | 483mm     | No         |
| 30219-144      | 483mm     | No         |
| 40304-078      | 483mm     | No         |
| 40304-081      | 483mm     | No         |
| 40304-083      | 483mm     | No         |

## ADDITIONAL PRODUCT DETAILS

Please order 19" assembly kit separately.

## DIAGRAMS

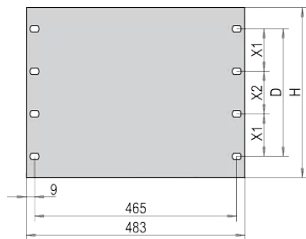

**WARNING**

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

**Europe**

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

**Asia**

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

**Middle East & India**

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**