 


# EuropacPRO 19" Subrack Kit for Backplane, Shielded

EMC Shielded subrack for backplane mounting, rear side covered by a rear panel.



## CERTIFICATIONS



## FEATURES

Subrack with side panel type F ("flexible"), front 19" bracket included, depth-adjustable 19" bracket sold separately (not included in items delivered)

Supplied as space-saving flat-pack

Modifications such as cutouts, different finishes or dimensions available

EMC of approximately 40 dB at 1 GHz, 30 dB at 2 GHz, assuming that the front is covered with shielded front panels, testing in accordance with VG 95373 part 15

IP 20, in accordance with IEC 60529

Aluminum construction

Internal and external dimensions in accordance with: IEC 60297-3-100, -101, IEEE 1101.1

Rear horizontal rail for backplane mounting with insulation strip

Horizontal rail type "light"

## SPECIFICATIONS

<b>Material:</b>	Aluminum
<b>Finish:</b>	Anodized; Passivated

**Product Type:** Subrack/Chassis

**EMC Shielding:** Yes

Table 1/2

Catalog Number	Rack Height	Depth (D)	Package Quantity	For Mounting	Board Depth	EMC Gasket Type
24563-142	3U	235mm	1	Backplane	160mm, 220mm	Textile
24563-143	3U	295mm	1	Backplane	160mm, 220mm, 280mm	Textile
24563-144	3U	355mm	1	Backplane	160mm, 220mm, 280mm	Textile
24563-145	3U	415mm	1	Backplane	160mm, 220mm, 280mm	Textile
24563-146	3U	475mm	1	Backplane	160mm, 220mm, 280mm	Textile
24563-442	6U	235mm	1	Backplane	160mm, 220mm	Textile
24563-443	6U	295mm	1	Backplane	160mm, 220mm, 280mm	Textile
24563-444	6U	355mm	1	Backplane	160mm, 220mm, 280mm	Textile
24563-445	6U	415mm	1	Backplane	160mm, 220mm, 280mm	Textile
24563-446	6U	475mm	1	Backplane	160mm, 220mm, 280mm	Textile

Table 2/2


Catalog Number	Handle Included	Mounting	Complies With	Rack Width	Static Load	Quick Ship
24563-142	No	Rack	IEC 60297-3-103	84HP	11kg	No
24563-143	No	Rack	IEC 60297-3-103	84HP	11kg	No
24563-144	No	Rack	IEC 60297-3-103	84HP	11kg	No

CatalogNumber	HandleIncluded	Mounting	Complies With	Rack Width	Static Load	Quick Ship
24563-145	No	Rack	IEC 60297-3-103	84HP	11kg	No
24563-146	No	Rack	IEC 60297-3-103	84HP	11kg	No
24563-442	No	Rack	IEC 60297-3-103	84HP	11kg	No
24563-443	No	Rack	IEC 60297-3-103	84HP	11kg	No
24563-444	No	Rack	IEC 60297-3-103	84HP	11kg	No
24563-445	No	Rack	IEC 60297-3-103	84HP	11kg	No
24563-446	No	Rack	IEC 60297-3-103	84HP	11kg	No

## ADDITIONAL PRODUCT DETAILS

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

## DIAGRAMS

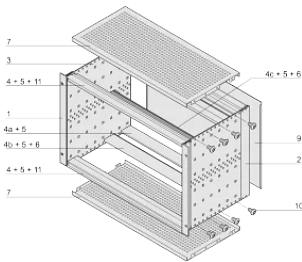

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**