


# EuropacPRO Advanced EMC 45 Top and Bottom Covers, Screwed to Side Panel, Ø 2.3mm

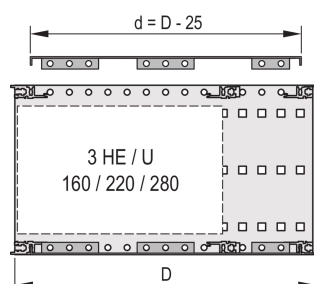

A cover plate is used for electromagnetic shielding or as mechanical protection. The cover can be screwed onto the side panel.

## CERTIFICATIONS



## FEATURES

Top and bottom covers with EMC and airflow optimized perforation, fulfills the requirements of the fire safety standard EN 62368-1, perforation diameter Ø 2.3mm, degree 50%

For variable positioning of horizontal rails e.g. for PCBs with standard formats

Cover plate for bolting to the side panel

Suitable for use with all horizontal rails, besides Rugged

## SPECIFICATIONS

|                        |             |
|------------------------|-------------|
| <b>Material:</b>       | Aluminum    |
| <b>Product Type:</b>   | Cover Plate |
| <b>Product Family:</b> | EuropacPRO  |
| <b>Finish:</b>         | Passivated  |
| <b>Type:</b>           | Perforated  |
| <b>Works With:</b>     | Subracks    |

Table 1/1

| Catalog Number | Rack Width | Depth | Package Quantity | Package Unit | Quick Ship |
|----------------|------------|-------|------------------|--------------|------------|
|----------------|------------|-------|------------------|--------------|------------|

|           |      |          |   |      |    |
|-----------|------|----------|---|------|----|
| 24563-555 | 36HP | 175mm    | 2 | Pair | No |
| 24563-556 | 36HP | 235mm    | 2 | Pair | No |
| 24563-560 | 42HP | 175mm    | 2 | Pair | No |
| 24563-561 | 42HP | 235mm    | 2 | Pair | No |
| 24563-562 | 42HP | 275mm    | 2 | Pair | No |
| 24563-563 | 42HP | 277.75mm | 2 | Pair | No |
| 24563-564 | 42HP | 295mm    | 2 | Pair | No |
| 24563-660 | 63HP | 175mm    | 2 | Pair | No |
| 24563-661 | 63HP | 235mm    | 2 | Pair | No |
| 24563-662 | 63HP | 275mm    | 2 | Pair | No |
| 24563-663 | 63HP | 295mm    | 2 | Pair | No |
| 24563-760 | 84HP | 175mm    | 2 | Pair | No |
| 24563-761 | 84HP | 235mm    | 2 | Pair | No |
| 24563-762 | 84HP | 275mm    | 2 | Pair | No |
| 24563-763 | 84HP | 277.75mm | 2 | Pair | No |
| 24563-764 | 84HP | 295mm    | 2 | Pair | No |
| 24563-765 | 84HP | 355mm    | 2 | Pair | No |
| 24563-766 | 84HP | 415mm    | 2 | Pair | No |
| 24563-767 | 84HP | 495mm    | 2 | Pair | No |

**WARNING**

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

**Europe**

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

**Asia**

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

**Middle East & India**

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**