


Eurorack 19" Panel/Slide Mount

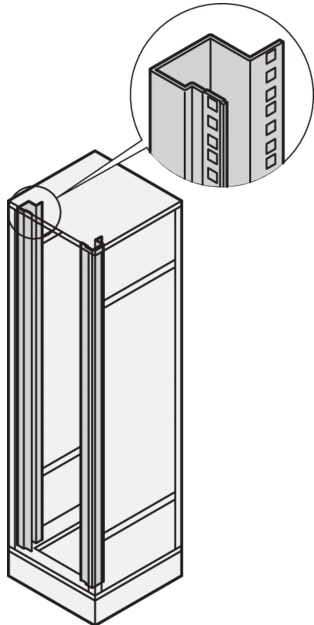

Slide mount with adjustable increments.

CERTIFICATIONS



FEATURES

For depth-adjustable mounting

St, 1.5 mm, with EIA cut-out

For the assembly of a third 19" plane 1 pair of 19" panel/slide mounts and 2 pairs of depth members are needed

SPECIFICATIONS

Table 1/2

Catalog Number	Rack Height	Material	Finish	Package Quantity	Height	Product Type
22117-356	38U	Steel	Aluminum-Zinc Plated	2	1798mm	Slide Mount

Table 2/2

Catalog Number	Type	Quick Ship
22117-356	19" Panel Slide Mount	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE