

# Plug-In Unit Front Panel for Static Trapezoid Handle



The front panel enables the assembly of a plastic or Alu-profile static trapezoid handle. The front panel cannot be shielded with a textile gasket.

## CERTIFICATIONS



## FEATURES

Front panel, unshielded

Front panel, Al, 2.5 mm, front anodized, conductive

## SPECIFICATIONS

|                        |                              |
|------------------------|------------------------------|
| <b>Depth (D):</b>      | 2.5mm                        |
| <b>Material:</b>       | Aluminum                     |
| <b>Finish:</b>         | Anodized; Passivated         |
| <b>Accessory Type:</b> | Front panel                  |
| <b>Product Type:</b>   | Front Panel                  |
| <b>Type:</b>           | Front Panel for Handle (PIU) |

Table 1/3

| Catalog Number | Rack Height | Rack Width | Package Quantity | Handle Type | Mounting | Front Finish |
|----------------|-------------|------------|------------------|-------------|----------|--------------|
|----------------|-------------|------------|------------------|-------------|----------|--------------|

|           |    |      |   |                                              |                |          |
|-----------|----|------|---|----------------------------------------------|----------------|----------|
| 30847-602 | 3U | 3HP  | 1 | Trapezoid,<br>Static,<br>Aluminum<br>Profile | Screw-on Front | Anodized |
| 30847-603 | 3U | 4HP  | 1 | Trapezoid,<br>Static,<br>Aluminum<br>Profile | Screw-on Front | Anodized |
| 30847-604 | 3U | 5HP  | 1 | Trapezoid,<br>Static,<br>Aluminum<br>Profile | Screw-on Front | Anodized |
| 30847-605 | 3U | 6HP  | 1 | Trapezoid,<br>Static,<br>Aluminum<br>Profile | Screw-on Front | Anodized |
| 30847-606 | 3U | 7HP  | 1 | Trapezoid,<br>Static,<br>Aluminum<br>Profile | Screw-on Front | Anodized |
| 30847-607 | 3U | 8HP  | 1 | Trapezoid,<br>Static,<br>Aluminum<br>Profile | Screw-on Front | Anodized |
| 30847-608 | 3U | 10HP | 1 | Trapezoid,<br>Static,<br>Aluminum<br>Profile | Screw-on Front | Anodized |
| 30847-609 | 3U | 12HP | 1 | Trapezoid,<br>Static,<br>Aluminum<br>Profile | Screw-on Front | Anodized |
| 30847-625 | 6U | 3HP  | 1 | Trapezoid,<br>Static,<br>Aluminum<br>Profile | Screw-on Front | Anodized |
| 30847-626 | 6U | 4HP  | 1 | Trapezoid,<br>Static,<br>Aluminum<br>Profile | Screw-on Front | Anodized |
| 30847-627 | 6U | 5HP  | 1 | Trapezoid,<br>Static,<br>Aluminum<br>Profile | Screw-on Front | Anodized |
| 30847-628 | 6U | 6HP  | 1 | Trapezoid,<br>Static,<br>Aluminum<br>Profile | Screw-on Front | Anodized |

|           |    |      |   |                                              |                |          |
|-----------|----|------|---|----------------------------------------------|----------------|----------|
| 30847-629 | 6U | 7HP  | 1 | Trapezoid,<br>Static                         | Screw-on Front | Anodized |
| 30847-630 | 6U | 8HP  | 1 | Trapezoid,<br>Static,<br>Aluminum<br>Profile | Screw-on Front | Anodized |
| 30847-631 | 6U | 10HP | 1 | Trapezoid,<br>Static,<br>Aluminum<br>Profile | Screw-on Front | Anodized |
| 30847-632 | 6U | 12HP | 1 | Trapezoid,<br>Static                         | Screw-on Front | Anodized |

Table 2/3

| Catalog Number | Rear Finish | Treated Edges | Complies With   | EMC Shielding | Height (H) | Width (W) |
|----------------|-------------|---------------|-----------------|---------------|------------|-----------|
| 30847-602      | Conductive  | No            | IEC 60297-3-101 | No            | 128.4mm    | 14.9mm    |
| 30847-603      | Conductive  | No            | IEC 60297-3-101 | No            | 128.4mm    | 20mm      |
| 30847-604      | Conductive  | No            | IEC 60297-3-101 | No            | 128.4mm    | 25mm      |
| 30847-605      | Conductive  | No            | IEC 60297-3-101 | No            | 128.4mm    | 30.1mm    |
| 30847-606      | Conductive  | No            | IEC 60297-3-101 | No            | 128.4mm    | 35.2mm    |
| 30847-607      | Conductive  | No            | IEC 60297-3-101 | No            | 128.4mm    | 40.3mm    |
| 30847-608      | Conductive  | No            | IEC 60297-3-101 | No            | 128.4mm    | 50.5mm    |
| 30847-609      | Conductive  | No            | IEC 60297-3-101 | No            | 128.4mm    | 60.6mm    |
| 30847-625      | Conductive  | No            | IEC 60297-3-101 | No            | 261.8mm    | 14.9mm    |
| 30847-626      | Conductive  | No            | IEC 60297-3-101 | No            | 261.8mm    | 20mm      |
| 30847-627      | Conductive  | No            | IEC 60297-3-101 | No            | 261.8mm    | 25mm      |
| 30847-628      | Conductive  | No            | IEC 60297-3-101 | No            | 261.8mm    | 30.1mm    |


| CatalogNumber | Rear Finish | Treated Edges | Complies With   | EMC Shielding | Height (H) | Width (W) |
|---------------|-------------|---------------|-----------------|---------------|------------|-----------|
| 30847-629     | Conductive  | No            | IEC 60297-3-101 | No            | 261.8mm    | 35.2mm    |
| 30847-630     | Conductive  | No            | IEC 60297-3-101 | No            | 261.8mm    | 40.3mm    |
| 30847-631     | Conductive  | No            | IEC 60297-3-101 | No            | 261.8mm    | 50.5mm    |
| 30847-632     | Conductive  | No            | IEC 60297-3-101 | No            | 261.8mm    | 60.6mm    |

Table 3/3

| Catalog Number | Quick Ship |
|----------------|------------|
| 30847-602      | No         |
| 30847-603      | No         |
| 30847-604      | No         |
| 30847-605      | No         |
| 30847-606      | No         |
| 30847-607      | No         |
| 30847-608      | No         |
| 30847-609      | No         |
| 30847-625      | No         |
| 30847-626      | No         |
| 30847-627      | No         |
| 30847-628      | No         |
| 30847-629      | No         |

| Catalog Number | Quick Ship |
|----------------|------------|
| 30847-630      | No         |
| 30847-631      | No         |
| 30847-632      | No         |

## DIAGRAMS

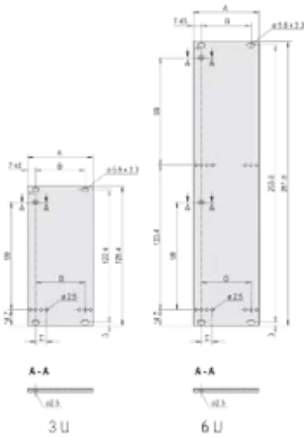

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:

[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**