


# Copper Busbars, WO60

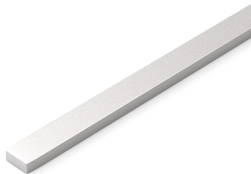

Standard tin-plated Cu busbars used together with busbar supports.

## INDUSTRY STANDARDS

---

UL

CSA

GL

## FEATURES

---

Description: Tin-plated Cu busbars. The Cu busbar is effectively protected against aggressive media.

Material: Cu-ETP R300 (EN13601), tinned

Length: 2400 mm

Pack quantity: 1 pc.

Approvals: CSA, UL, GL

## SPECIFICATIONS

| Table 1/1      |        |       |        |          |        |                    |
|----------------|--------|-------|--------|----------|--------|--------------------|
| Catalog Number | Height | Width | Depth  | Material | Finish | Cross Section      |
| 01618          | 5mm    | 12mm  | 2400mm | Copper   | Tinned | 60mm <sup>2</sup>  |
| 01619          | 5mm    | 15mm  | 2400mm | Copper   | Tinned | 75mm <sup>2</sup>  |
| 01620          | 5mm    | 20mm  | 2400mm | Copper   | Tinned | 100mm <sup>2</sup> |
| 01621          | 5mm    | 25mm  | 2400mm | Copper   | Tinned | 125mm <sup>2</sup> |
| 01623          | 10mm   | 12mm  | 2400mm | Copper   | Tinned | 120mm <sup>2</sup> |
| 01622          | 5mm    | 30mm  | 2400mm | Copper   | Tinned | 150mm <sup>2</sup> |
| 01624          | 10mm   | 20mm  | 2400mm | Copper   | Tinned | 200mm <sup>2</sup> |
| 01625          | 10mm   | 30mm  | 2400mm | Copper   | Tinned | 300mm <sup>2</sup> |

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**