

# PPP Parallel Plastic Screw-In Plug for P13/P14, Worldwide Design



## FEATURES

Designed for use with the P13/P14 coupler families

Designed to keep dirt, water and concrete slurry out of the coupler during the concrete pour

Color coded for the appropriate coupler size

## SPECIFICATIONS

**Design Version:** Worldwide (Globally Available Materials)

Table 1/2


Catalog Number	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)	Height (H)	Color
EL16PPPNB100	16 mm	#5	15M	30 mm	13 mm	Black
EL12PPPNB100	12 mm	#4	10M	25 mm	13 mm	Red
EL40PPPNB25	40 mm			70 mm	16 mm	Green
EL20PPPNB100	20 mm	#6	20M	35 mm	16 mm	Yellow
EL22PPPNB100	22 mm	#7		40 mm	16 mm	Blue

CatalogNumber	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)	Height (H)	Color
EL25PPPNB100	25 mm	#8	25M	45 mm	16 mm	Red
EL28PPPNB50	28 mm	#9	30M	50 mm	16 mm	Black
EL32PPPNB50	32 mm	#10		60 mm	16 mm	Yellow
EL36PPPNB25	36 mm	#11	35M	65 mm	16 mm	Blue

Table 2/2

Catalog Number	Package Quantity
EL16PPPNB100	100
EL12PPPNB100	100
EL40PPPNB25	25
EL20PPPNB100	100
EL22PPPNB100	100
EL25PPPNB100	100
EL28PPPNB50	50
EL32PPPNB50	50
EL36PPPNB25	25

DIAGRAMS

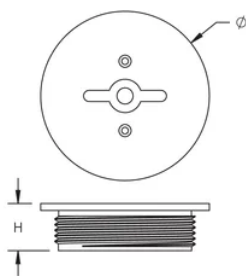

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE