


# PropacPRO Desktop Case, Unshielded, 2 U, 42 HP, 266 mm

**CATALOG NUMBER**

**14576-021**

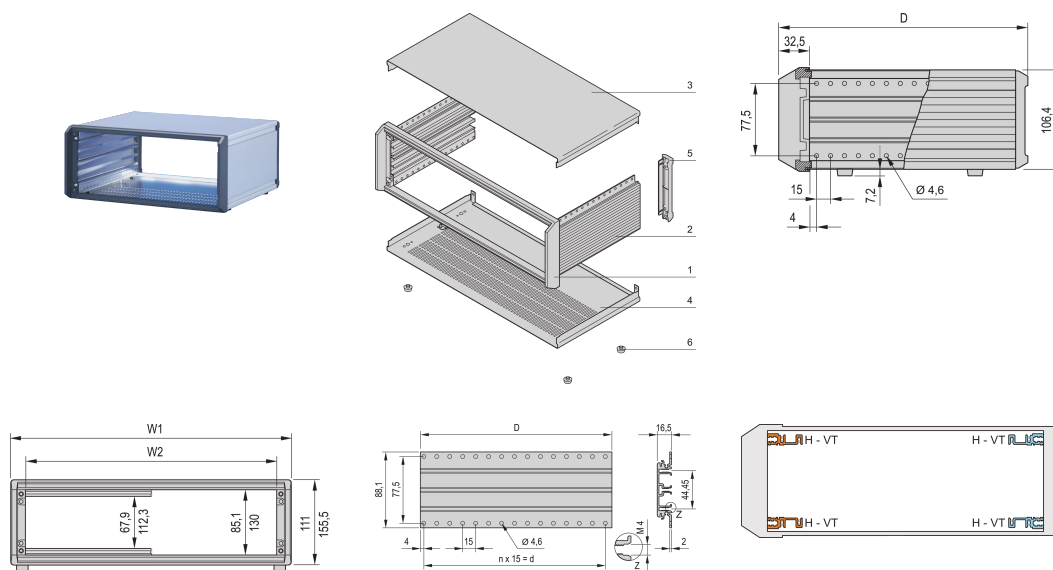

The nVent SCHROFF PropacPRO case provides electronics protection for 19" and individual electronic assemblies. The aluminum die cast frames and profile sidepanels guarantee a robust solution. In addition an extensive accessory range is available.

## CERTIFICATIONS



## FEATURES

Desktop case for individual assembly

Ventilation slots in base plate

## Retrofittable EMC shielding

Prepared for GND/earthing

Conforms with DIN EN 62368-1

**PRODUCT ATTRIBUTES**

---

|                                                 |
|-------------------------------------------------|
| Rack Height: 2U                                 |
| Rack Width: 42HP                                |
| Depth: 266mm                                    |
| Package Quantity: 1                             |
| Usable Height: 85.1mm                           |
| Usable Width: 219mm                             |
| Front Frame Construction: Single Piece          |
| Cooling Option: No                              |
| Complies With: IEC 60297-3-101                  |
| EMC Shielding: No (Retrofittable)               |
| Finish: Passivated; Powder Coated               |
| Height: 111mm                                   |
| Material: Aluminum                              |
| Product Family: PropacPRO                       |
| Product Type: Case                              |
| Protection Rating: IP20                         |
| Static Load: 25kg                               |
| Type: Case for Individual Electronic Components |
| Width: 257mm                                    |
| Net Weight: 1.66kg                              |

**ADDITIONAL PRODUCT DETAILS**

---

Case, 2 U with side panel for tip-up carrying handle on request.

**WARNING**

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**