


Varistar 19" Shelf, Telescopic, 30 kg

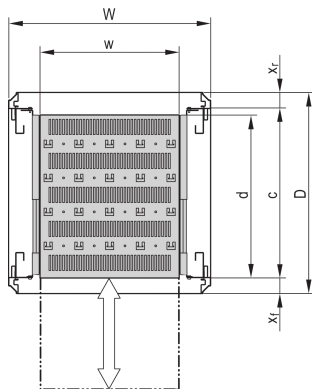

Varistar 19" Shelf, Stationary with 30 KG load capacity, perforated for ease of assembly.

CERTIFICATIONS



FEATURES

Static load-carrying capacity at full extension 30 kg

Perforated for assembling cable ties

Mounting height 1 U, for mounting on four 19" panel/slide mounts

Incl. telescopic slides

Hammer head perforation to fix cable ties

SPECIFICATIONS

Product Type: Shelf

Material: Steel

Table 1/2

Catalog Number	Width	Depth	Package Quantity	Color	Color Code	Finish
21130-344	417mm	700mm	1	Black Grey	RAL 7021	Powder Coated

CatalogNumber	Width	Depth	Package Quantity	Color	Color Code	Finish
21130-342	417mm	500mm	1	Black Grey	RAL 7021	Powder Coated
22130-345	417mm	582mm	1	Light Grey	RAL 7035	Powder Coated
22130-344	417mm	582mm	1	Light Grey	RAL 7035	Powder Coated
22130-343	417mm	482mm	1	Light Grey	RAL 7035	Powder Coated
21130-345	417mm	700mm	1	Black Grey	RAL 7021	Powder Coated
21130-343	417mm	500mm	1	Black Grey	RAL 7021	Powder Coated
22130-342	417mm	382mm	1	Light Grey	RAL 7035	Powder Coated

Table 2/2		
Catalog Number	Type	Quick Ship
21130-344	Telescopic Shelf, Reduced Depth	No
21130-342	Telescopic Shelf, Reduced Depth	No
22130-345	Telescopic Shelf	No
22130-344	Telescopic Shelf, Reduced Depth	No
22130-343	Telescopic Shelf	No
21130-345	Telescopic Shelf	No
21130-343	Telescopic Shelf	No
22130-342	Telescopic Shelf, Reduced Depth	No

ADDITIONAL PRODUCT DETAILS

Mounting bracket for assembly of the telescopic slide on the frame please order separately.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE