

Ground Rod Driving Point for Ground Rod, Sectional Internal Thread



FEATURES

Threaded ground rod driving point for use only with internally threaded ground rods


SPECIFICATIONS

Material: Steel

Table 1/1

Catalog Number	Article Number	For Use With	Length (L)	Thread Length (TL)	Diameter (Ø)	Thread Size (TS)
SPK15	710120	SSR16 and SCR15 Internally Threaded Ground Rods	42mm	20mm	15 mm	M10
SPK20	710130	SSR20 Internally Threaded Ground Rod	51mm	20mm	20 mm	M10

DIAGRAMS

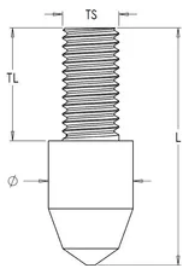

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE