

# nVent CADDY Single-Arm Cable Pressure Clip



The nVent CADDY Single-Arm Cable Pressure Clip is a sustainable, ready-to-install metal clip allowing for easy cable installation with one hand. This solution securely supports small-sized cable bundles in crowded spaces—such as flush to ceilings, above suspended ceilings. The Single-Arm Pressure Clip’s unique design creates an option to combine two single-arm clips within seconds—ultimately doubling the cable capacity per a single fixing point, reducing the number of required stock parts, and saving contractors time on the job. Featuring a low-profile design, this cable pressure clip is a more durable alternative to commonly used plastic solutions and offers an ideal solution for electrical and datacom applications.

## FEATURES

Gangable/Two-in-one solution; two nVent CADDY Single-Arm Cable Pressure Clips can be combined by hand to instantly double the cable capacity per single fixing point

Compatible with direct fastening and traditional anchoring

Reusable in case of nail misfire

More robust and durable than plastic pressure clips

Rounded edges help prevent cable damage

Cables are neatly installed, providing a consistent and professional appearance

Low-profile design allows for installation in tight spaces

Made of 100% recyclable materials

## SPECIFICATIONS

**Finish:** Pregalvanized

**Material:** Steel

Table 1/2

| Catalog Number | Article Number | Hole Size (HS) | Length (L) | Height (H) | Width (W) | Diameter 1 (Ø1) |
|----------------|----------------|----------------|------------|------------|-----------|-----------------|
| OAB8DF         | 182068         | 4.8 mm         | 115mm      | 15mm       | 30mm      | 4 - 10 mm       |


| CatalogNumber | Article Number | Hole Size (HS) | Length (L) | Height (H) | Width (W) | Diameter 1(Ø1) |
|---------------|----------------|----------------|------------|------------|-----------|----------------|
| OAB8          | 182067         | 7.5 mm         | 115mm      | 15mm       | 30mm      | 4 - 10 mm      |

| Table 2/2      |                |                 |                |
|----------------|----------------|-----------------|----------------|
| Catalog Number | Article Number | Diameter 2 (Ø2) | Cable Capacity |
| OAB8DF         | 182068         | 5 - 11 mm       | 8              |
| OAB8           | 182067         | 5 - 11 mm       | 8              |

### ADDITIONAL PRODUCT DETAILS

\*Cable capacity based on a 10mm diameter cable

### DIAGRAMS

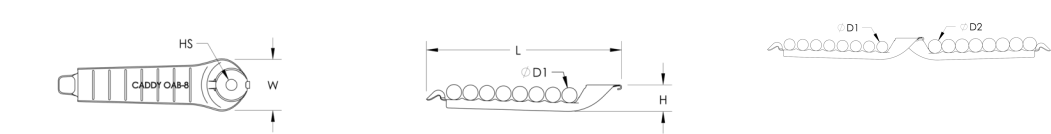

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

#### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

#### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

#### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE

