


# PEMSA Wire Basket Tray Universal Tray Splice

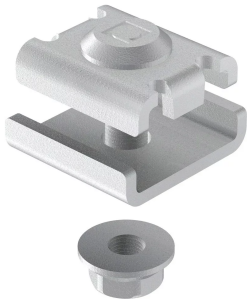

## CERTIFICATIONS



## FEATURES

Significant mechanical joint strength

Robust steel design and construction

IEC 61537 load rating and earthing compliant

## SPECIFICATIONS


Table 1/2

Catalog Number	Article Number	Material	Color	Finish	A	B
WBTUNVSPLEG	820700	Steel		Electrogalvanized	24.5 mm	23 mm
WBTUNVSPLBG	820701	Steel	Black	Electrogalvanized	24.5 mm	23 mm
WBTUNVSPLS4	820702	Stainless Steel 304 (EN 1.4301)			24.5 mm	23 mm

Table 2/2

Catalog Number	Article Number	Rod Size (RS)	Certifications
WBTUNVSPLEG	820700	6	DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG, CE, CADDY EU WBT UNV
WBTUNVSPLBG	820701	6	CE, CADDY EU WBT UNV, DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG
WBTUNVSPLS4	820702	6	UKCA, CADDY WBTUNVSPLS4, CE, CADDY WBTUNVSPLS4

## DIAGRAMS

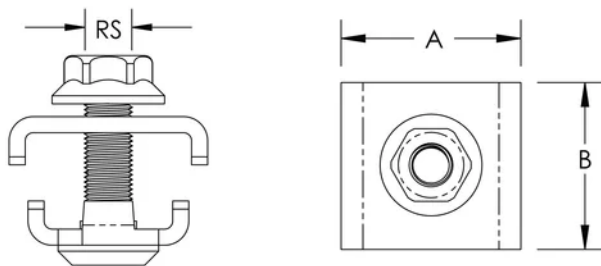

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

