


Varistar Top Cover Fan, Height 38 mm, 162 m³/h

CATALOG NUMBER

23130-165

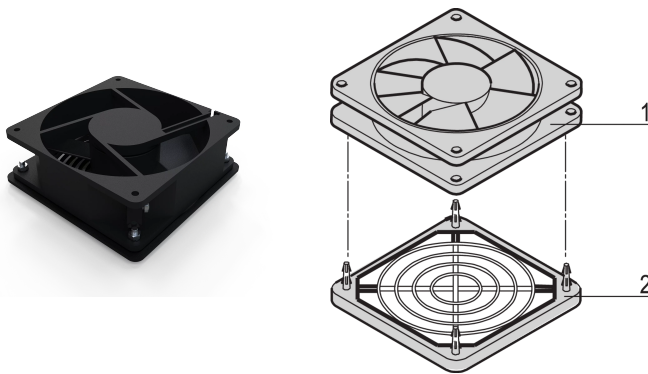

Top covers with fans are compact active cooling units which do not consume rack space. The Varistar fan for top cover comes with high specifications.

CERTIFICATIONS



FEATURES

Varistar Top Cover Fan, Height 38 mm, 162 m³/h

PRODUCT ATTRIBUTES

Product Type: Fan

Product Family: Varistar

Works With: Varistar CP

Voltage AC: 230V

Depth: 119mm

Frequency: 50/60 Hz

Airflow @ 50 Hz: 162m³/h

Airflow @ 60 Hz: 192m³/h

Noise Level @ 50 Hz: 37dB(A)

Noise Level @ 60 Hz: 41dB(A)

Power @ 50 Hz: 15W

Power @ 60 Hz: 14W

Max Static Pressure @ 50 Hz: 73Pa

Max Static Pressure @ 60 Hz: 88Pa

Ambient Temperature: 70°C

Height: 38mm

Width: 119mm

Finish: Powder Coated

Gross Weight: 0.66kg

Material: Steel

Package Quantity: 1

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE