


# Joint Bond T6 Mold Welder Frame Assembly, Signal

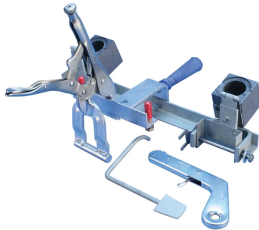

## FEATURES

Replacement welder frame assembly for T6 joint bond welders

Includes frame with mold lid, mold handle, mold cleaner and flint ignitor

## SPECIFICATIONS

**Rail Type:** 85 lb to 141 lb T-Rail Sections

**Material:** Graphite;Steel;Thermoplastic

Table 1/1

Catalog Number	Article Number	Bond Terminal Style	Conductor Size	Conductor Outer Diameter, Nominal	Welder Style
SBXST6AX		XS	3/16" Bondstrand	4.76mm	T6
SBXST6CX		XS	3/16" Bondstrand	4.76mm	T6
SBXT6CE	161120	W	50 mm <sup>2</sup> Ropelay	9.13mm	T6

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause

product malfunction, property damage, serious bodily injury and death and/or void your warranty.

⚠ WARNING: This product can expose you to chemicals including diisononyl phthalate, which is known to the State of California to cause cancer. For more information go to [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov).

**North America**

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

**Europe**

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

**Europe**

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

**APAC**

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE