


# nVent CADDY Standard Prefab Assemblies

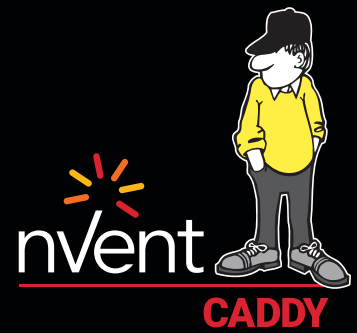

CONNECT AND PROTECT

## Available at Graybar


### Why nVent CADDY Standard Prefab Assemblies?

With nVent CADDY Pre-Assembled Products, you can win back valuable time on the job site otherwise spent assembling multi-part components.

- Standardize basic assemblies for common on-the-job installations
- Expedite installation while maintaining consistency and optimizing skilled labor
- Save time by reducing the amount of assembly required and expand your prefabrication capabilities
- Meet your budget targets while controlling for inventory and maximizing productivity
- Reduce waste and create a more efficient process

### TB1624HD BETWEEN STUD AND T-GRID APPLICATIONS

- Rigid and versatile – add/remove boxes quickly and easily
- Prefab tab to prevent disassembly during transport, but allows for sliding on main bracket prior to final securement
- Bracket will telescope and allow for easy positioning within wall stud
- Box center plates slide to desired position prior to final securement

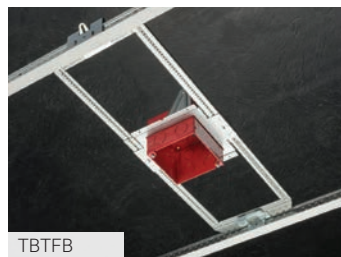

TBTFB




TBP4DPP1

Part Number	GBID	Description
TBP4DM1	26565575	TB1624HD (TB), TB45P (P), 4"-2 1/8" BOX (4D), 3/4" ONE GANG MR (M1)
TBP4D	26565574	TB1624HD (TB), TB45P (P), 4"-2 1/8" BOX (4D)
TBP4DV1	26565579	TB1624HD (TB), TB45P (P), 4"-2 1/8" BOX (4D), ONE GANG ADJ MR (V1)
TBP4DPP1	26565578	TB1624HD (TB), TB45P (P), 4"-2 1/8" BOX (4D), TB45P (P), 4 11/16" BOX (P1)
TBP4DM1PP1M5	26565576	TB1624HD (TB), TB45P (P), 4"-2 1/8" BOX (4D), 3/4" ONE GANG MR (M1), TB45P (P), 4 11/16" BOX (P1), 3/4" ONE GANG MR (M5)
TBFB	26565573	TB1624HD (TB), TB435FB (FB) FIRE ALARM BOX ASSEMBLY
TBTFB	26565580	TB1624HD (TB), TBTG T-GRID CLIP (T), TB435FB (FB) FIRE ALARM BOX ASSEMBLY
TBP4DPD1	26565577	TB1624HD (TB), TB45P (P), 4"-2 1/8" BOX (4D), TB45P (P), 4-11/16" DATA BOX (D1)

Electrical boxes contain ground wire unless noted with N at the end of the part. D1 data box does not contain a ground.

## ON STUD BRACKET TB45PK

- Integral far side support for installation on any stud depth
- Extruded holes allow mounting of mud rings for power and data applications
- Snaps onto TB1624HD bracket for between stud applications

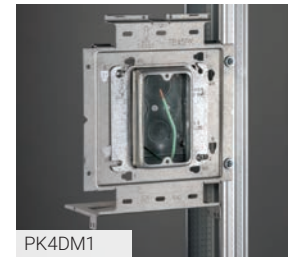

PK4DM1

Part Number	GBID	Description
PK4D	26565562	TB45PK (PK), 4"-2 1/8" BOX (4D)
PK4DM1	26565563	TB45PK (PK), 4"-2 1/8" BOX (4D), 3/4" ONE GANG MR (M1)
PK4DM2	26565564	TB45PK (PK), 4"-2 1/8" BOX (4D), 3/4" TWO GANG MR (M2)
PK4DV1	26565565	TB45PK (PK), 4"-2 1/8" BOX (4D), ONE GANG ADJ MR (V1)
PK4DV2	26565566	TB45PK (PK), 4"-2 1/8" BOX (4D), TWO GANG ADJ MR (V2)
PKD1	26565567	TB45PK (PK), 4-11/16" DATA BOX (D1)
PKD1M5	26565568	TB45PK (PK), 4-11/16" DATA BOX (D1), 3/4" ONE GANG MR (M5)
PKP1	26565569	TB45PK (PK), 4 11/16" BOX (P1)
PKP1M5	26565570	TB45PK (PK), 4 11/16" BOX (P1), 3/4" ONE GANG MR (M5)
PKP1M6	26565571	TB45PK (PK), 4 11/16" BOX (P1), 3/4" TWO GANG MR (M6)

## BETWEEN STUD BRACKET TSRBS1625

- Adjusts 16 to 25" spacing
- Accommodates up to 6-gang box in 16" stud spacing or up to 10-gang in 24" stud spacing
- Open design allows a variety of positions for box location
- Easy to adjust after the electrical box is installed
- For use with 4" square and 4 11/16" boxes and mud rings



TR4DM1P1M5

Part Number	GBID	Description
TR4DM1	26565583	TSRBS1625 (TR), 4"-2 1/8" BOX (4D), 3/4" ONE GANG MR (M1)
TR4DM1P1M5	26565584	TSRBS1625 (TR), 4"-2 1/8" BOX (4D), 3/4" ONE GANG MR (M1), 4 11/16" BOX (P1), 3/4" ONE GANG MR (M5)

## BETWEEN STUD BRACKET TSGB1624 WITH TSGLDR1

- Adjusts 16 to 24" spacing Glider attachment for easy positioning of the box
- Can be mounted to face or inside of stud
- Adjustable for non-standard stud spacing
- Requires only a screw gun to install




TS1L4D

Part Number	GBID	Description
TS1L4D	26565585	TSGB1624 (TS), TSGLDR1 (1L), 4 X 2-1/8 DP BOX (4D)
TS1L4DM1	26565586	TSGB1624 (TS), TSGLDR1 (1L), 4 X 2-1/8 DP BOX (4D), 3/4" ONE GANG MR (M1)

Electrical boxes contain ground wire unless noted with N at the end of the part. D1 data box does not contain a ground.

## ON STUD BRACKET UUM


- Rigid design, no far side support required when mounted on left or right of stud
- Use with any 4" or 4-11/16" boxes
- Works with both standard and adjustable single gang mudrings

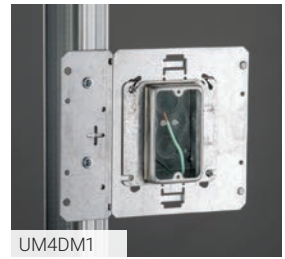

Part Number	GBID	Description
UM4DM1	26565587	UUM (UM), 4"-2 1/8" BOX (4D), 3/4" ONE GANG MR (M1)
UM4DM2	26565588	UUM (UM), 4"-2 1/8" BOX (4D), 3/4" TWO GANG MR (M2)
UM4DV1	26565589	UUM (UM), 4"-2 1/8" BOX (4D), ONE GANG ADJ MR (V1)
UMP1M5	26565590	UUM (UM), 4 11/16" BOX (P1), 3/4" ONE GANG MR (M5)
UMP1M6	26565591	UUM (UM), 4 11/16" BOX (P1), 3/4" TWO GANG MR (M6)

## BETWEEN STUD BRACKET RBS16HD, RBS24HD (0 INDICATES NO BOX BRACKET OPENING)

- Heavy duty design with increased strength, twice as strong as the first generation RBS
- Accepts vertically or horizontally mounted single and double gang adjustable mud rings
- Designed to work with snap-in-place first means of support for conduit and cables

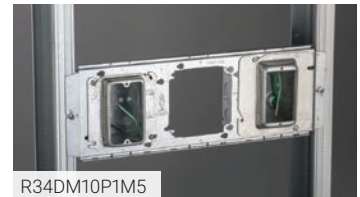

Part Number	GBID	Description
R34D00	26565572	RBS16HD (R3), 4"-2 1/8" BOX (4D)
R34D0D1	26565532	RBS16HD (R3), 4"-2 1/8" BOX (4D) LEFT, 4-11/16" DATA BOX (D1) RIGHT
R34D0P1	26565533	RBS16HD (R3), 4"-2 1/8" BOX (4D) LEFT, 4 11/16" BOX (P1) RIGHT
R34DM100	26565534	RBS16HD (R3), 4"-2 1/8" BOX (4D), 3/4" ONE GANG MR (M1) LEFT
R34DM10P1M5	26565535	RBS16HD (R3), 4"-2 1/8" BOX (4D), 3/4" ONE GANG MR (M1) LEFT, 4 11/16" BOX (P1), 3/4" ONE GANG MR (M5) RIGHT
R34DM200	26565536	RBS16HD (R3), 4"-2 1/8" BOX (4D), 3/4" TWO GANG MR (M2) LEFT
R34DV100	26565537	RBS16HD (R3), 4"-2 1/8" BOX (4D), ONE GANG ADJ MR (V1) LEFT
R34DV200	26565538	RBS16HD (R3), 4"-2 1/8" BOX (4D), TWO GANG ADJ MR (V2) LEFT
R44D4D0D1	26565539	RBS24HD (R4), 4"-2 1/8" BOX (4D), FAR LEFT, 4"-2 1/8" BOX (4D) LEFT, 4-11/16" DATA BOX (D1) FAR RIGHT

## BETWEEN STUD BRACKETS FB16 AND FB16 + FB16FS FLOOR STAND + OPTIONAL FIRST MEANS

- Stamped with A- and B-side markings for all box types and configurations – no need for removal of screws, simply flip and it's ready to use
- Bracket is completely flat, no offset
- Floor stand positions boxes 18-1/2" from the floor for consistent placement



Part Number	GBID	Description
F3A4D0P1	26565556	FB16 (F3) A-SIDE (A), 4"-2 1/8" BOX (4D) LEFT, 4 11/16" BOX (P1) RIGHT
F3A4DM10P1M5	26565557	FB16 (F3) A-SIDE (A), 4"-2 1/8" BOX (4D), 3/4" ONE GANG MR (M1) LEFT, 4 11/16" BOX (P1), 3/4" SG MUDRING (M5) 3/4" ONE GANG MR (M5) RIGHT
F3AFS	26565558	FB16 (FS) A-SIDE (A), FB16FS (FS)
F3AFSC1	26565559	F3 (FB16) A-SIDE (A), FS (FB16FS), C1 (CJ6+FB16FM) LEFT
F3BFS	26565560	FB16 (FS) B-SIDE (B), FB16FS (FS)
F3BFSC1	26565561	F3 (FB16) B-SIDE (B), FS (FB16FS), C1 (CJ6+FB16FM) LEFT

Electrical boxes contain ground wire unless noted with N at the end of the part. D1 data box does not contain a ground.

## T-GRID BRACKETS 512HD, 512SAT, TCB

- Brackets mount quickly to T-grid
- Drop wire for independent support
- Supports multiple box installations
- The 512SAT bracket accommodates multiple electrical box depths and acoustical tile options  
It can be easily adjusted with the push of a button
- TCB bracket supports fans, fixtures and luminaries from ceiling



5HCD

Part Number	GBID	Description
5HCD	26565554	512HD (5H), OCTAGONAL BOX 2-1/8" DEEP (CD)
5HCS	26565555	512HD (5H), OCTAGONAL BOX 1-1/2" DEEP (CS)
STBRN	26565550	512SAT (ST), BX435RD (BR), NO GROUND (N)
STP1	26565551	512SAT (ST), 4 11/16" BOX (P1)
TCCDAR	26565581	TCB (TC), OCTAGONAL BOX 2-1/8 DEEP (CD), ADJ ROUND MR (AR)
TCCSAR	26565582	TCB (TC), OCTAGONAL BOX 1-1/2 DEEP (CS), ADJ ROUND MR (AR)

## BOX/CONDUIT SECUREMENT PLATFORM BCSP SERIES

- Ideal single-rod securement for box/conduit installations
- Accommodates a wide range of electrical boxes
- Contains embedded rivet nut – no penetrating the electrical box
- Includes electrical box alignment pockets
- Tool-free securement options



SP45D5

Part Number	GBID	Description
SP454D	26565540	BCSP45 (SP45), 4"-2 1/8" BOX (4D)
SP45D5	26565541	BCSP45 (SP45), 5" DATA BOX (D5)
SP45P1	26565542	BCSP45 (SP45), 4 11/16" BOX (P1)
SP45R254D	26565543	BCSP45RS25 (SP45R25), 4 X 2-1/8 DP BOX (4D)
SP45R25D5	26565544	BCSP45RS25 (SP45R25), 5" DATA BOX (D5)
SP45R25P1	26565545	BCSP45RS25 (SP45R25), 4-11/16 BOX (P1)
SP612AS08	26565546	BCSP612 (SP612) HOFFMAN AS08, 8" BOX (AS08)
SP612AS12	26565547	BCSP612 (SP612) HOFFMAN AS12, 12" BOX (AS12)
SP612RB08	26565548	BCSP612 (SP612) 8" BOX (RB08)
SP612RB12	26565549	BCSP612 (SP612) 12" BOX (RB12)

Electrical boxes contain ground wire unless noted with N at the end of the part. D1 data box does not contain a ground.

For additional customization needs, ask your local Graybar or nVent CADDY sales representative about **nVent CADDY Custom Prefab Assemblies** made to the exact specifications or design requirements of your project!

DISTRIBUTED BY



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER**