

# APX External Vertical Wall Bracket



## FEATURES

Saddle support for C-Profiles and strut

Complete with fixings

## SPECIFICATIONS

Table 1/2


Catalog Number	Article Number	Material	Finish	Channel Type	Strut Type	Height (H)
APXE23EG	584710	Steel	Electrogalvanized	E2L, E2, E3		114 mm
APXE01EG	584715	Steel	Electrogalvanized	E0L, E0, E1		114 mm
APXE4STRUTEG	584725	Steel	Electrogalvanized	E4	A (41 x 41 mm), C (21 x 41 mm)	144 mm
APXSTRUTS6	584820	Stainless Steel 316 (EN 1.4401)			A (41 x 41 mm), C (21 x 41 mm)	144 mm

Table 2/2

Catalog Number	Article Number	Width (W)	Thickness (T)	A	B	C
APXE23EG	584710	50 mm	5 mm	36 mm	12 mm	19 mm

CatalogNumber	Article Number	Width (W)	Thickness (T)	A	B	C
APXE01EG	584715	50 mm	5 mm	31 mm	12 mm	19 mm
APXE4STRUTEG	584725	70 mm	5 mm	43 mm	12 mm	19 mm
APXSTRUTS6	584820	70 mm	6 mm	43 mm	12 mm	19 mm

## DIAGRAMS

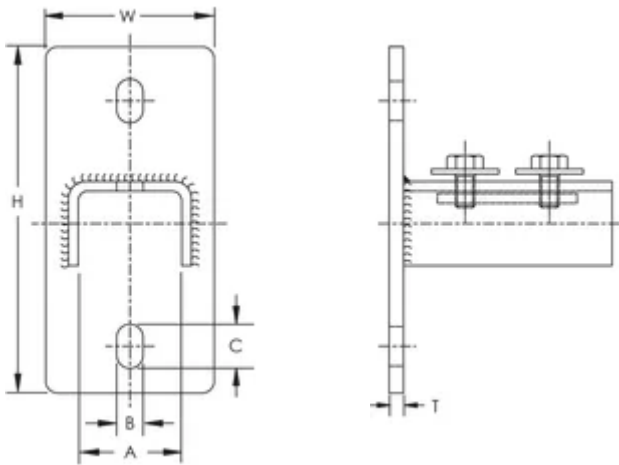

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**

