

# PEMSA Wire Basket Tray Splice Bar

## Data Solutions



### CERTIFICATIONS



### FEATURES

Added mechanical splice strength

Works with wide range of tray sizes and configurations

IEC 61537 load rating and earthing compliant

### SPECIFICATIONS

**Finish:** Electrogalvanized


**Material:** Steel

Table 1/1

Catalog Number	Article Number	Color	Length (L)	Width (W)	Thickness (T)	Slot Size (SS)
WBTSPBAR30 OBG	820703	Black	300mm	22mm	1.5mm	7 x 28 mm

CatalogNumber	Article Number	Color	Length (L)	Width (W)	Thickness (T)	Slot Size (SS)
WBTSPBAR30 0EG	820704		300mm	22mm	1.5mm	7 x 28 mm

DIAGRAMS

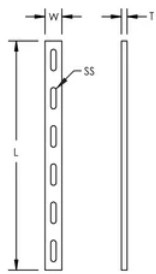

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE